


# FEED THROUGH TERMINAL BLOCKS



AVK Series  
Starts at  
**0.48¢**  
each for pkg  
of 100




- Screw Connection
- Vibration Resistant, Maintenance Free Connection
- Self-Locking Zinc Plated Wire Clamps
- 600V Rated, UL 94 V2 Polyamide 6.6 Housing
- Full Line of Accessories—End Plates, Cross Connectors and Marking Tags
- Stock Colors in Grey, Blue and Red
- Also Available in Yellow, Beige and Green

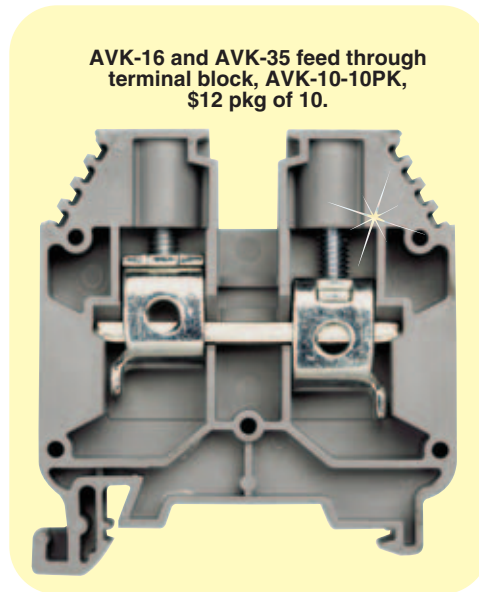


AVK-16 and AVK-35 feed through terminal block, AVK-10-10PK, \$12 pkg of 10.

All models shown smaller than actual size.


AVK Series feed through terminal blocks are screw connection style with vibration resistant wire clamps and are DIN rail mounted. The AVK terminal blocks come in all wire ranges and no pre-treatment of the wire is necessary, even for stranded wire. A full line of accessories are available including end plates, end brackets, cross connectors and marking tags. The AVK series also includes 3 size grounding terminal blocks.

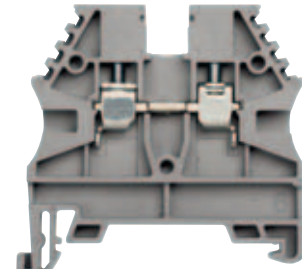

AVK-2.5 to AVK-10 feed through terminal block, AVK-2.5-50PK, \$30 pkg of 50.

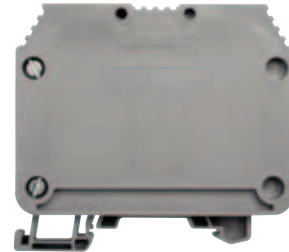

AVK-70-10PK feed through terminal block, \$150 pkg of 10.

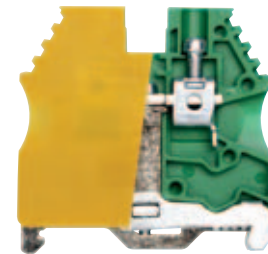

AVK-2.5/4T-10PK ground terminal block, \$30 pkg of 10.

## SPECIFICATIONS

ELECTRICAL RATINGS	AVK-2.5	AVK-4	AVK-6	AVK-10	AVK-16	AVK-35	AVK-70
Voltage/Current	750V/26 A	750V/34 A	750V/44 A	750V/61 A	750V/82 A	750V/135 A	750V/192 A
VDE (IEC 60947-7-1)	750V/24 A	750V/32 A	630V/41 A	630V/57 A	750V/76 A	750V/125 A	
UL/CSA	600V/20 A	600V/30 A	600V/50 A	600V/65 A	600V/85 A	600V/115 A	600V/175 A
ATEX	630V/21 A	400V/28 A	630V/36 A	500V/50 A	630V/66 A	630V/109 A	1000V/167 A
Insulation Strip Length	10 mm	10 mm	12 mm	12 mm	16 mm	18 mm	20 mm
AWG	26-12	26-10	26-8	16-6	14-4	8-1	6-2/0
Width	5 mm	6 mm	8 mm	10 mm	12 mm	16 mm	22 mm
End Plate-Partition	AVK-EP-210	AVK-EP-210	AVK-EP-210	AVK-EP-210	AVK-EP-16	Included	Included
Cross-Connectors/2	OM-474122	OM-474132	OM-474142	OM-474152	OM-474162	OM-474172	—
Cross-Connectors/3	OM-474123	OM-474133	OM-474143	OM-474153	OM-474163	OM-474173	—
Cross-Connectors/4	OM-474124	OM-474134	OM-474144	OM-474154	OM-474164	OM-474174	—
Cross-Connectors/10	OM-474129	OM-474139	OM-474149	OM-474159	OM-474169	OM-474179	—

GROUNDING TERMINAL BLOCKS	AVK-2.5/4T	AVK-6/10T	AVK-16/35T
Insulation Strip Length	10 mm	12 mm	18 mm
AWG	26-10	16-8	10-2
Width	6 mm	10 mm	16 mm
End Plate-Partition	Included	Included	Included

OM-474123-10PK, 3 piece cross connector, \$14.25 for pkg of 10.

Shown larger than actual size.



**To Order** (Specify Model Number)**MOST POPULAR MODELS HIGHLIGHTED!**

MODEL NO.	PRICE	AMPS	AWG	MODEL NO.	PRICE	AMPS	AWG
AVK-2.5-100PK	\$48	20	26-12	AVK-10-10PK	\$15	65	16-6
AVK-2.5-50PK	30	20	26-12	AVK-16-25PK	49	85	12-4
AVK-4-100PK	58	30	26-10	AVK-16-10PK	25	85	12-4
AVK-4-50PK	35	30	26-10	AVK-35-25PK	125	115	10-2
AVK-6-50PK	38	50	26-8	AVK-35-10PK	60	115	10-2
AVK-6-25PK	23	50	26-8	AVK-70-10PK	150	175	6-2/0
AVK-10-50PK	60	65	16-6	AVK-70	20	175	6-2/0

Note: Standard color is grey, for other colored terminal blocks add suffix "-R" for red, "-B" for blue, "-Y" for yellow, "-G" for green and "-BE" for beige, no additional cost.

**GROUNDING TERMINAL BLOCKS**

MODEL NO.	PRICE	AWG	MODEL NO.	PRICE	AWG
AVK-2.5/4T-10PK	\$30	26-10	AVK-6/10T-25PK	\$65.00	16-8
AVK-2.5/4T-50PK	118	26-10	AVK-16/35T	8.50	10-2
AVK-6/10T-10PK	30	16-8	AVK-16/35T-25PK	174.00	10-2

**ACCESSORIES**

MODEL NO.	PRICE	DESCRIPTION
AVK-EP-210-10PK	\$4.00	End plate-partition for AVK-2.5 thru AVK-10, 10 pkg
AVK-EP-16-10PK	6.00	End plate-partition for AVK-16, 10 pkg
T-BLK-EB-10PK	5.00	DIN rail end bracket, 10 pcs per pkg

**CROSS-CONNECTORS**

MODEL NO.	PRICE	PCS/PKG	POSITIONS	MODEL NO.	PRICE	PCS/PKG	POSITIONS
OM-474122-10PK	\$9.50	10	2	OM-474152-10PK	\$21.75	10	2
OM-474123-10PK	14.25	10	3	OM-474153-10PK	30.00	10	3
OM-474124-10PK	22.75	10	4	OM-474154-10PK	40.00	10	4
OM-474129-3PK	13.50	3	10	OM-474159-3PK	28.50	3	10
OM-474132-10PK	18.75	10	2	OM-474162-10PK	22.75	10	2
OM-474133-10PK	27.25	10	3	OM-474163-10PK	30.00	10	3
OM-474134-10PK	36.25	10	4	OM-474164-10PK	40.00	10	4
OM-474139-3PK	26.00	3	10	OM-474169-3PK	28.50	3	10
OM-474142-10PK	20.00	10	2	OM-474172-10PK	14.00	10	2
OM-474143-10PK	29.50	10	3	OM-474173-10PK	21.25	10	3
OM-474144-10PK	38.00	10	4	OM-474174-10PK	25.50	10	4
OM-474149-3PK	26.50	3	10	OM-474179-3PK	18.50	3	10

MARKING TAGS - 50 PER CARD	PRICE	DESCRIPTION
MKR-NO-PRINT	\$3.00	Marking tag without print
MKR-1-10	3.00	Marking tag 1 to 10
MKR-11-20	3.00	Marking tag 11 to 20
MKR-1-50	3.00	Marking tag 1 to 50
MKR-51-100	3.00	Marking tag 51 to 100
MKR-101-150	3.00	Marking tag 101 to 150
MKR-151-200	3.00	Marking tag 151 to 200
MKR-201-250	3.00	Marking tag 201 to 250

Ordering Examples: AVK-2.5-100PK, package of 100 feed through terminal blocks for 26-12 AWG rated at 20 A, AVK-EP-210-10PK, package of 10 end plates for AVK-2.5 through AVK-10, and OM-474123-10PK, package of 10 three-position cross connectors, \$48 + 4 + 14.25 = \$66.25. AVK-35-10PK, package of 10 feed through terminal blocks for 10-2 AWG rated at 115 A, MKR-1-10, 1 card of 50 marker tags printed with numbers 1 to 10, \$60 + 3 = \$63.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters