

GENERAL PURPOSE AIR FILTER/REGULATORS FOR COMPRESSED AIR



**B07 Series
Starts at
\$48**


**Most
Economical**

B07-201-MILA,
\$48, shown
smaller than
actual size.



- Full Flow Gauge Ports
- Excellent Flow and Regulation Characteristics
- Water and Partial Removal
- 5 Micron Filter Element
- ¼" PTF Gauge Ports
- Maximum Pressure 8.6 bar (125 psig)
- Transparent Polycarbonate Bowl

General purpose air filter/regulators are designed for in-line use as a single regulating control filtering source for compressed air. This air regulator/filter is full flow ported for excellent flow and regulation characteristics. Available with a ¼" PTF thread, a transparent bowl, relieving diaphragm, gauge, and a 0.3 to 8.6 bar (5 to 125 psig) pressure adjustment range. It is suitable for a wide range of pneumatic tools and components and an excellent point of use filter/regulator. This unit can be panel mounted with a 30 mm (1.19") diameter mounting hole or can be used with the optional bracket and panel nut.

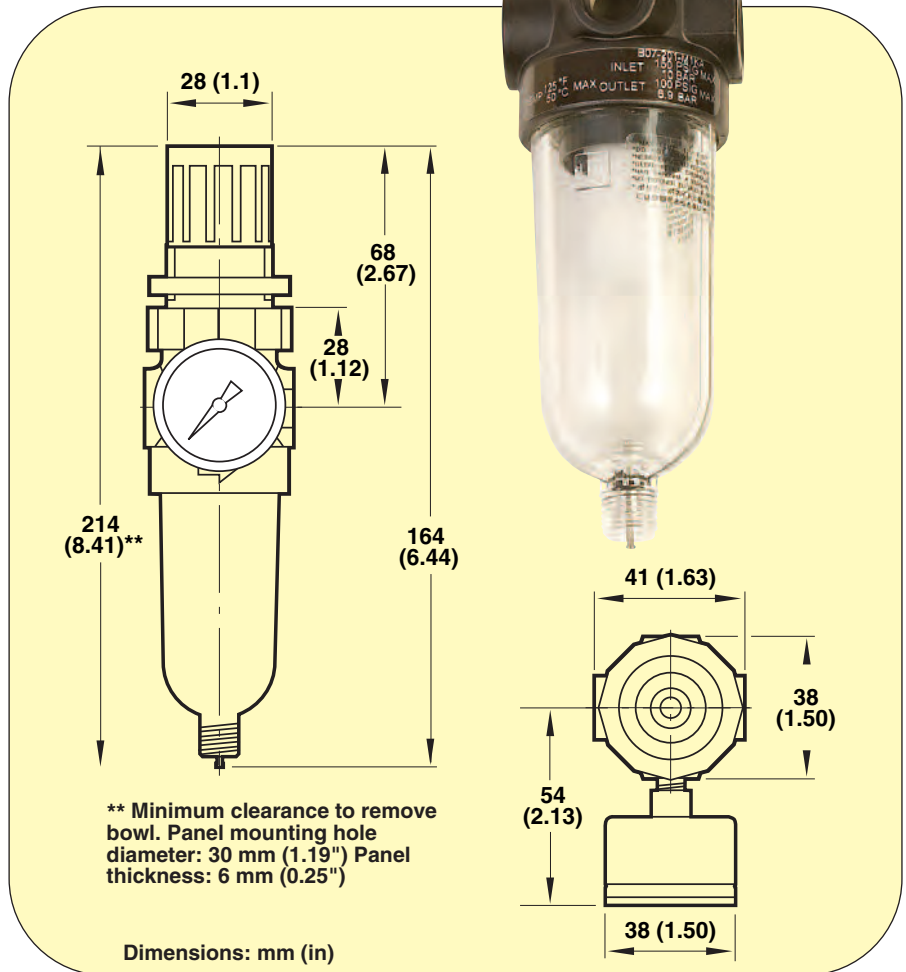

SPECIFICATIONS

Operating Temperature*:

-34 to 50°C (30 to 125°F)

Maximum Pressure: 8.6 bar (125 psig)

Materials:

Body: Zinc

Bonnet: Acetal

Bowl: Transparent Polycarbonate

Valve Seat: Acetal

Element:

B07: Sintered polypropylene

* Air supply must be dry enough to avoid ice formation at temperatures below 2°C (35°F)

To Order (Specify Model Number)

AVAILABLE FOR FAST DELIVERY!

MODEL NO.	PRICE	PORT (in)	PSI	DESCRIPTION
B07-201-MILA	\$48	¼	125	Manual drain, no gauge
B07-202-A1KA	64	¼	100	Automatic drain, with gauge

ACCESSORIES

MODEL NO.	PRICE	DESCRIPTION
OM-AIR-18-025-003	\$6.25	Mounting bracket and plastic panel nut
AU-B79870309	3.00	¼ NPT O.D. ¼ NPT I.D. reducer bushing (set of 2)

Ordering Example: B07-202-A1KA, general purpose air filter/regulator with ¼" port and transparent bowl and OM-AIR-18-025-003, mounting bracket with panel nut, \$64 + 6.25 = \$70.25.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters