


**NEW**

**The Only HMI That Web-Enables Any Device for Remote Operation Across Your LAN or the Internet**

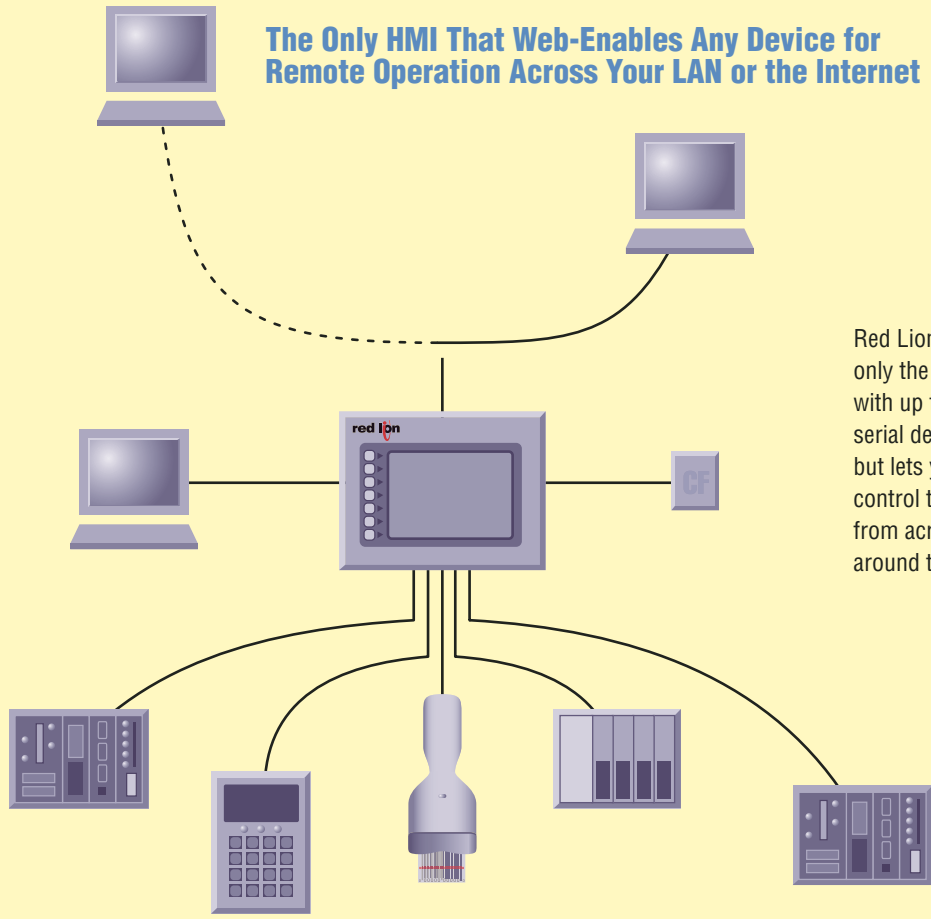

Red Lion's G3 HMI Series is not only the first to communicate with up to five different types of serial devices simultaneously, but lets you access, monitor and control these devices remotely—from across your network, or around the globe.

**Accessory Cables**

The following cables may be used to connect the G3 HMI, Data Station Plus or Red Lion Modular Controller Master to the listed device.

MODEL NO.	PRICE	DESCRIPTION	MODEL NO.	PRICE	DESCRIPTION
CBLAB001	\$41	Allen Bradley SLC-503 V DF 1	CBLOMR03	\$41	Omron C-SERIES RS422
CBLAB002	41	Allen Bradley PLC-5 V CHNL 0	CBLPROG0	41	RJ-11 PROG. Lead 10FT
CBLAB003	41	Allen Bradley DH48	CBLRLC00	31	485 G3 RJ45 - RL RJ11
CBLAB004	41	Allen Bradley PNLVW VIA DF1	CBLRLC01	21	RJ12-RJ12 1' Crossed
CBLGEF01	41	Ge Fanuc 90S V SNP	CBLRLC02	21	RJ12-RJ12 10' Crossed
CBLGEN01	41	RS232 TO MALE 9-PIN	CBLRLC03	21	RJ45-RJ45 1' Straight
CBLGEN02	41	RS232 Bare Wires	CBLRLC04	21	RJ45-RJ45 10' Straight
CBLGEN03	41	RS422/485 Bare Wires	CBLRLC05	31	RS485 Jumpered
CBLIDE01	41	Idec Micro 3	CBLRLC06	31	MC TO RED LION RJ11 RS485
CBLIDE02	41	Idec Micro 3C	CBLRLC07	31	RJ45-RJ45 6" Straight
CBLIDE03	41	Idec Micro Smart	CBLRLCS2	21	RJ12-RJ12 10' Straight
CBLKEY01	41	Keyence KV Series Cable	CBLSIE01	41	Siemens S7 PPI
CBLKOY00	41	Koyo Model 2xx	CBLSIE02	41	Siemens MPI with out Adaptor
CBLMAT01	41	Matsushita FP	CBLSIE03	308	Siemens MPI with Adaptor
CBLMAT02	41	Matsushita FP0	CBLSIE04	41	TI 545 on Port 1
CBLMDM00	41	Modem 9Pin Male	CBLSIE05	41	Siemens 545/555 RS232
CBLMDM01	41	Modem 25Pin Male	CBLSIE06	41	Siemens 545/555 - RS422
CBLMIT01	41	Misubishi FX	CBLSIE07	41	TI 500 Series
CBLMIT02	41	MIT FX0 and FX0N	CBLSIE08	41	Siemens-CP525 Comm Card
CBLMIT03	41	MIT A/Q	CBLSIE09	440	Siemens-S5 with Adaptor
CBLMOD01	41	Modicon (RS232)	CBLTEL00	57	G3 Telemechanique RS485
CBLOMR01	41	Omron (RS232)	CBLTEL01	57	G3 Telemechanique SLV 485
CBLOMR02	41	Omron SYS C200H-LK210	CBLYAS01	41	Yaskawa SMC3010



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters