



# TYPE 4 ENVIROLINE® JUNCTION ENCLOSURES WITH VIEWING WINDOW

*SCE-ELJW  
Series  
Starts at*  
**\$116**



SCE-1614ELJW, \$188, smaller than actual size.

- 0.063" Thick Carbon Steel
- Seams Continuously Welded and Ground Smooth
- Flange Trough Collar Around All Sides of Door Opening
- Oil-Resistant Gasket
- Standoffs Provided for Mounting Optional Sub-Panels
- Removable Hinges
- Doors Open 180°
- Black Mini-Quarter Turn Latches
- Optional Latches Available
- Latches Opened/Closed with a Screwdriver
- Sealing Washers, Hole Plugs and Mounting Feet Included
- Ground Stud on Door and Body

## Application


Designed to house electrical controls, instruments and components that require unrestricted viewing of the gauges or controls in areas which may be regularly hosed down or are in very wet or oily conditions. Provides protection from dust, dirt, oil, and water.

## Finish

ANSI-61 gray powder coat inside and out. Optional Subpanels are powder coated white.

## Industry Standards IS2

NEMA Type 4 and 12  
UL Type 4 and 12  
CSA Type 4 and 12  
IEC 60529 IP66

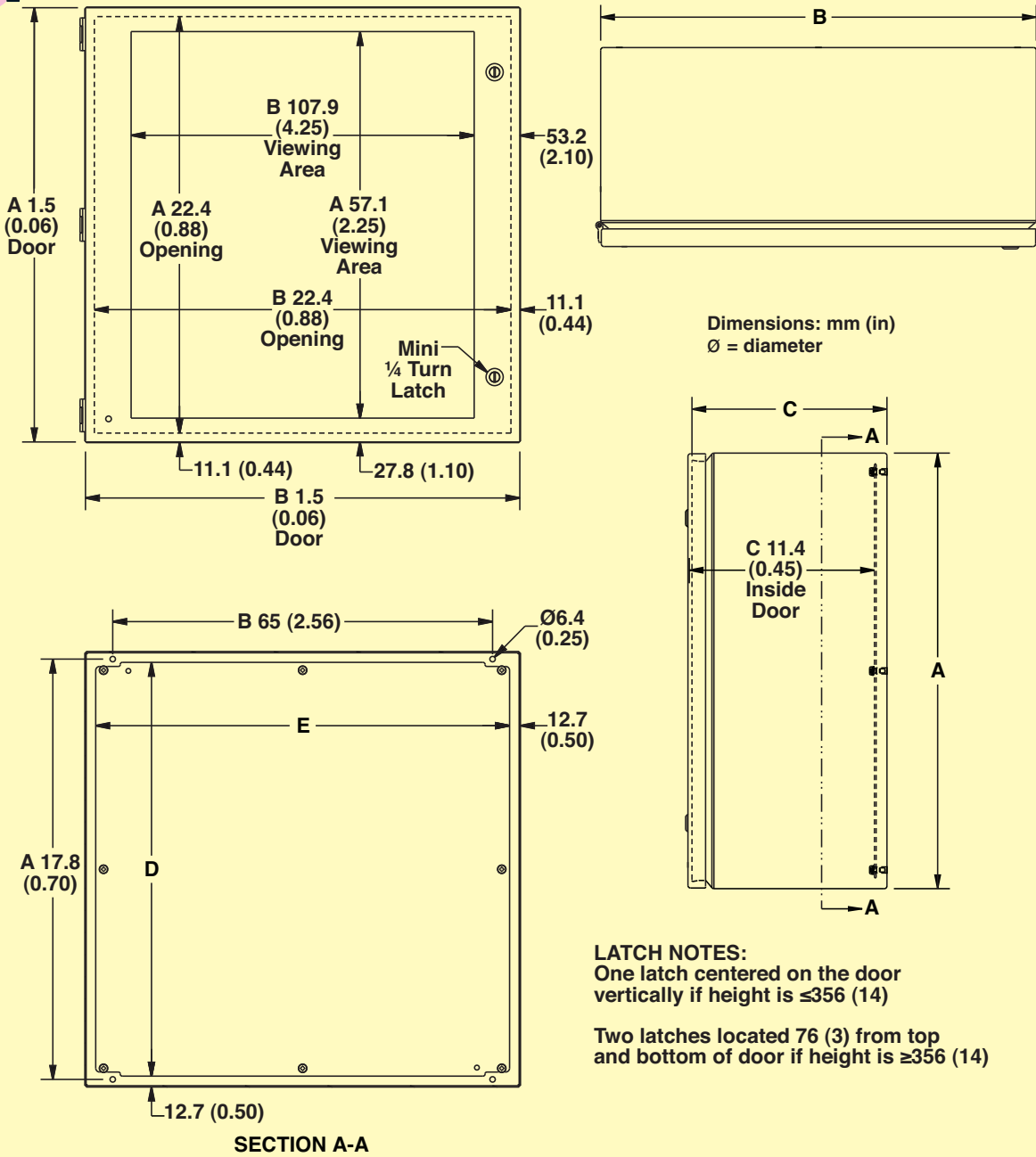

**LATCH NOTES:**  
 One latch centered on the door vertically if height is  $\leq 356$  (14)  
 Two latches located 76 (3) from top and bottom of door if height is  $\geq 356$  (14)

**To Order** (Specify Model Number)

**MOST POPULAR MODELS HIGHLIGHTED!**

ENCLOSURE		DIMENSIONS (in)				SUB-PANEL			
MODEL NO.	PRICE	HEIGHT (A)	WIDTH (B)	DEPTH (C)	VIEWING WINDOW	MODEL	PRICE	HEIGHT (A)	WIDTH (B)
SCE-1008ELJW	\$116	10	8	4	7.75 x 3.75	SCE-10P8J	\$5.90	9.25	7.25
SCE-10086ELJW	122	10	8	6	7.75 x 3.75	SCE-10P8J	5.90	9.25	7.25
SCE-1210ELJW	134	12	10	6	9.75 x 5.75	SCE-12P10J	8.00	11.25	9.25
SCE-12108ELJW	146	12	10	8	9.75 x 5.76	SCE-12P10J	8.00	11.25	9.25
SCE-1614ELJW	188	16	14	6	13.75 x 9.75	SCE-16P14J	20.75	15.25	13.25
SCE-16148ELJW	198	16	14	8	13.75 x 9.76	SCE-16P14J	20.75	15.25	13.25
SCE-20208ELJW	235	20	20	8	17.75 x 15.75	SCE-20P20J	37.00	19.25	19.25

Comes complete with operator's manual.

Ordering Examples: SCE-10086ELJW, NEMA Type 4 enclosure with viewing window, 10 H x 8 W x 6" D, \$122.

SCE-16148ELJW, NEMA Type 4 enclosure with viewing window, 16 H x 14 W x 8" D, \$198.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters