




WATER & SOIL INSTRUMENTS

Process Chlorine/Chlorine Dioxide Analyzer Accessories

CLE-DLG
\$625

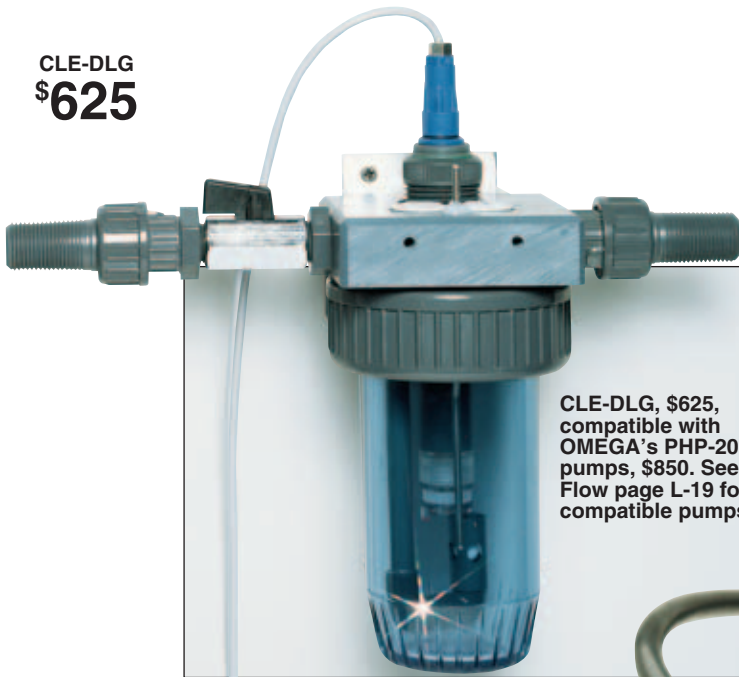

CLE-DLG, \$625, compatible with OMEGA's PHP-201B-P pumps, \$850. See the Flow page L-19 for compatible pumps.



Replaceable membrane.



CLE-23
sensor, \$1900.



Specifications

Sensor/Process Chamber

Principle of Operation: Amperometric, using PTFE polarographic membrane

Operating Temperature:

0 to 40°C (32 to 104°F)

Operating Pressure: Atmospheric

Process Connections: 1/2" MNPT

Max. Cable Length

(Sensor-Controller): 9.1 m (30')

To Order (Specify Model Number)

Model No.	Price	Description
CLE-23	\$1900	Mating sensor for CLCN-23H
CLE-DLG	625	Process chamber (sensor holder)
CLE-FTN	65	Sensor mounting hardware
CLE-CB6	360	1.8 m (6') interconnecting cable
CLE-CB15	375	4.5 m (15') interconnecting cable
CLE-CB30	395	9 m (30') interconnecting cable

Consumables

Model No.	Price	Description
CLE-23E	\$60	Chlorine sensor electrolyte (100 mL)
CLE-23CAP	180	Membrane cap for CLE-23 sensor



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters