

# NEMA 6 (IP68) SIDE MOUNTED LIQUID LEVEL SWITCHES

## For High, Low, or Intermediate Level Sensing

LVN-90 Series Starts at **\$34**



- ✓ NEMA 6 (IP68) Rated
- ✓ User Selectable, Normally Open or Normally Closed
- ✓ Mounts Horizontally

These liquid level switches are sealed with potting compound. The only path for liquid to the electrical switch would be through the wires. If the wires are terminated in an appropriate manner [eg. NEMA 6 (IP68) connectors], the level switch will meet or exceed a NEMA 6 (IP68) rating, making them suitable for submersion with years of worry free operation in moisture-laden environments. A sealed SPST switch provides consistent accuracy and high repeatability with the effects of shock, vacuum or vibration minimized.

The switch is extremely versatile since it is user selectable as a normally open or normally closed by simply reversing the float or the mounting of the switch. The standard NPT male fittings allow for quick installation in either the top or bottom of the tank or vessel.

### SPECIFICATIONS

#### Operating Temperature:

LVN-90 thru LVN-92: -40 to 82°C (-40 to 180°F)

LVN-93: -40 to 149°C (-40 to 300°F)

#### Maximum Pressure Rating:

100 to 500 psi






Mounting: 1/2" NPT

Switch: SPST

#### Switch Actuation:

Approximately 1/2 the float travel in liquid of 1.0 specific gravity

Lead Wires: 20 awg. 24" PVC

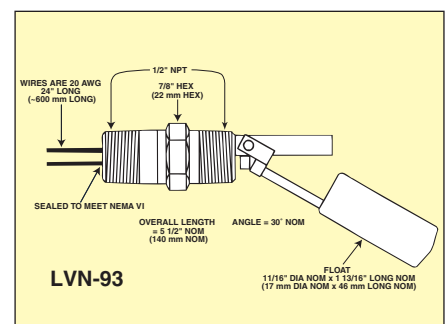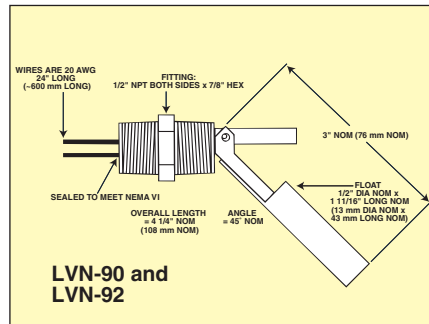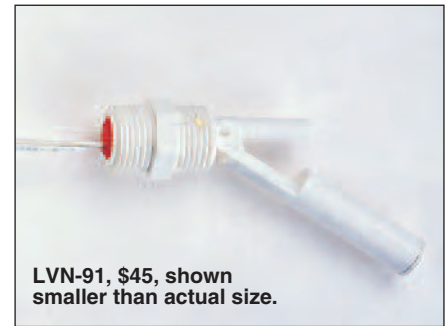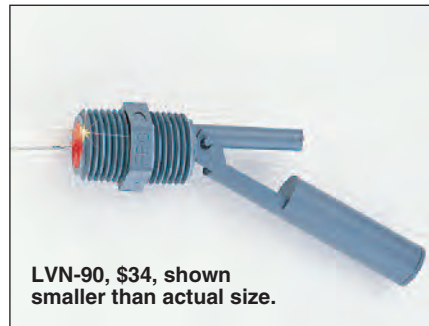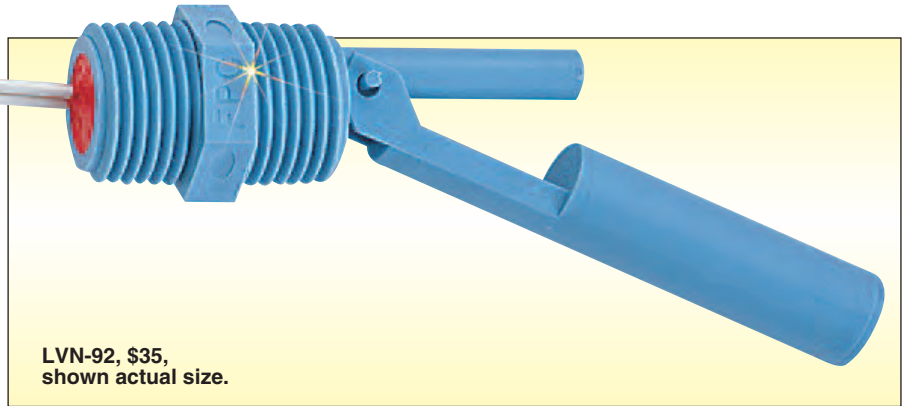

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)						
Model No.	Price	Switch Rating	Stem/Float	Maximum		Float Spec. Gravity
				Temp. °C (F)	Pres.	
LVN-90	\$34	50 VA	CPVC	82 (180)	100 psi	0.71
LVN-91	45	50 VA	PVDF	82 (180)	100 psi	0.88
LVN-92	35	50 VA	Polypropylene	82 (180)	100 psi	0.49
LVN-93	150	50 VA	316 SS	149 (300)	500 psi	0.85

Comes complete with operator's manual.

Ordering Examples: LVN-93, 316 stainless steel level switch, \$150.

LVN-90, CPVC level switch, \$34.

Recommended Reference Book: Introduction To Design For Civil Engineers, CE-1917, \$29. Visit [omega.com/bobi](http://omega.com/bobi) for Additional Books.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters