




OMEGAFLEX® MULTI-COLORED RIBBON POLYURETHANE TUBING

MCRPT Series
Starts at
\$37
for 50' Spool

- Faster Installation of Multiple Lines
- Eliminate Need for Additional Jacketing
- Color Code Identification
- All the Qualities of Polyurethane Tubing
- Kink and Abrasion Resistant
- Resistant to Chemicals, Water, Fuel, Oil and Fungus
- Outstanding Flexibility and Memory
- Temperature Range -40 to 73°C (-40 to 165°F)
- Vacuum Rating to 28" Hg

Multi-Color ribbon polyurethane tubing is a bonded ribbon of polyurethane tubing. The bonded tubing offers quicker installation and eliminates the need for additional handling to install spiral wrapping, channels or other bundling materials. The multi-color coded tubing provides quick identification of process lines for tracing and trouble shooting.

MULTI-COLOR RIBBON POLYURETHANE TUBING, 95A SHORE DUROMETER

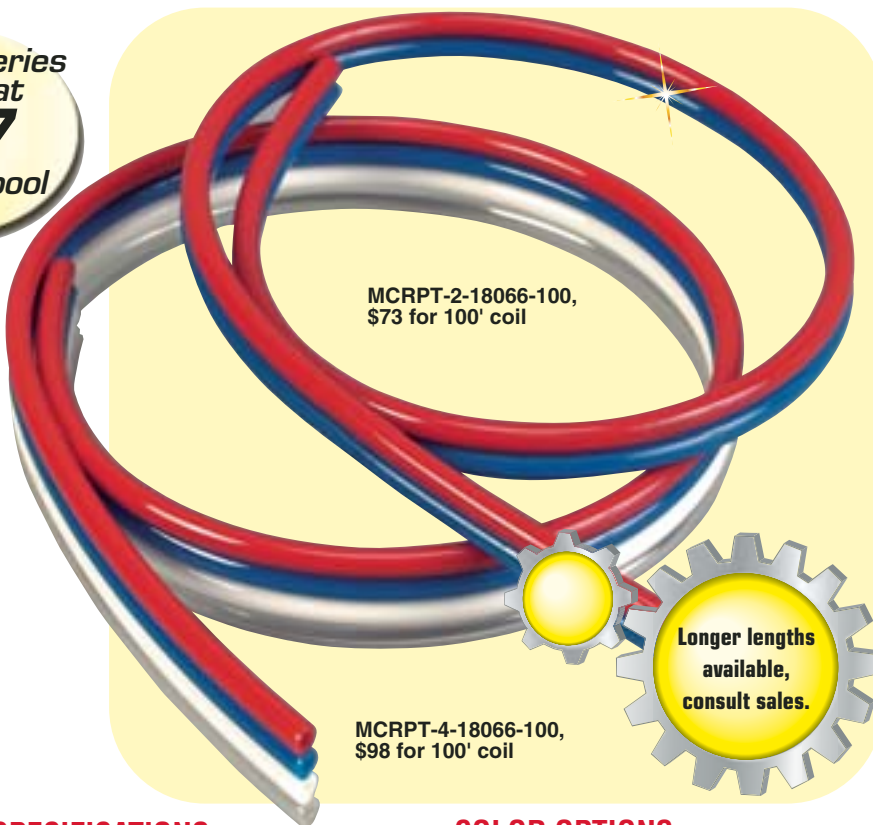

SPECIFICATIONS

Temperature Range: -40 to 73°C (-40 to 165°F)
Vacuum Rating: To 28" Hg
Working Pressure: 3:1 Safety factor

COLOR OPTIONS

TUBES	COLORS
2	Red, blue
4	Red, blue, white and clear

To Order (Specify Model Number)

MOST POPULAR MODELS HIGHLIGHTED!

MODEL NO.	PRICE	NUMBER OF TUBES	TUBE OD in	TUBE ID in	TUBE DIA. TOL. in	COIL LENGTH m (ft)	WALL in	WORKING PSI @ 24°C (75°F)	WEIGHT g (lbs)
MCRPT-2-18066-100	\$73	2	0.125	0.066	±0.005	30 (100)	0.030	255	400 (0.88)
MCRPT-2-18066-50	37	2	0.125	0.066	±0.005	15 (50)	0.030	255	200 (0.44)
MCRPT-4-18066-100	98	4	0.125	0.066	±0.005	30 (100)	0.030	255	800 (1.76)
MCRPT-4-18066-50	49	4	0.125	0.066	±0.005	15 (50)	0.030	255	400 (0.88)
MCRPT-2-532332-100	93	2	0.156	0.094	±0.005	30 (100)	0.031	210	565 (1.24)
MCRPT-2-532332-50	47	2	0.156	0.094	±0.005	15 (50)	0.031	210	280 (0.62)
MCRPT-4-532332-100	138	4	0.156	0.094	±0.005	30 (100)	0.031	210	1125 (2.48)
MCRPT-4-532332-50	69	4	0.156	0.094	±0.005	15 (50)	0.031	210	565 (1.24)
MCRPT-2-14160-100	142	2	0.250	0.160	±0.005	30 (100)	0.045	265	1660 (3.66)
MCRPT-2-14160-50	71	2	0.250	0.160	±0.005	15 (50)	0.045	265	835 (1.84)
MCRPT-4-14160-100	234	4	0.250	0.160	±0.005	30 (100)	0.045	175	3320 (7.32)
MCRPT-4-14160-50	117	4	0.250	0.160	±0.005	15 (50)	0.045	175	1660 (3.66)

Note: Specifications listed are meant only as a guide. Each user must test the tubing under their operating conditions to determine the tubing's suitability for the particular application.

Ordering Examples: MCRPT-4-18066-100, 30 m (100') coil, 4 tubes, 1/8" OD x 0.066" ID polyurethane tubing with working psi of 255, \$98.
MCRPT-2-532332-50, 15 m (50') coil, one red and one blue 5/32" OD x 3/32" ID 95A durometer polyurethane ribbon tubing, \$47.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters