




Pre-Mixed pH Calibration Solutions and Deionized Water

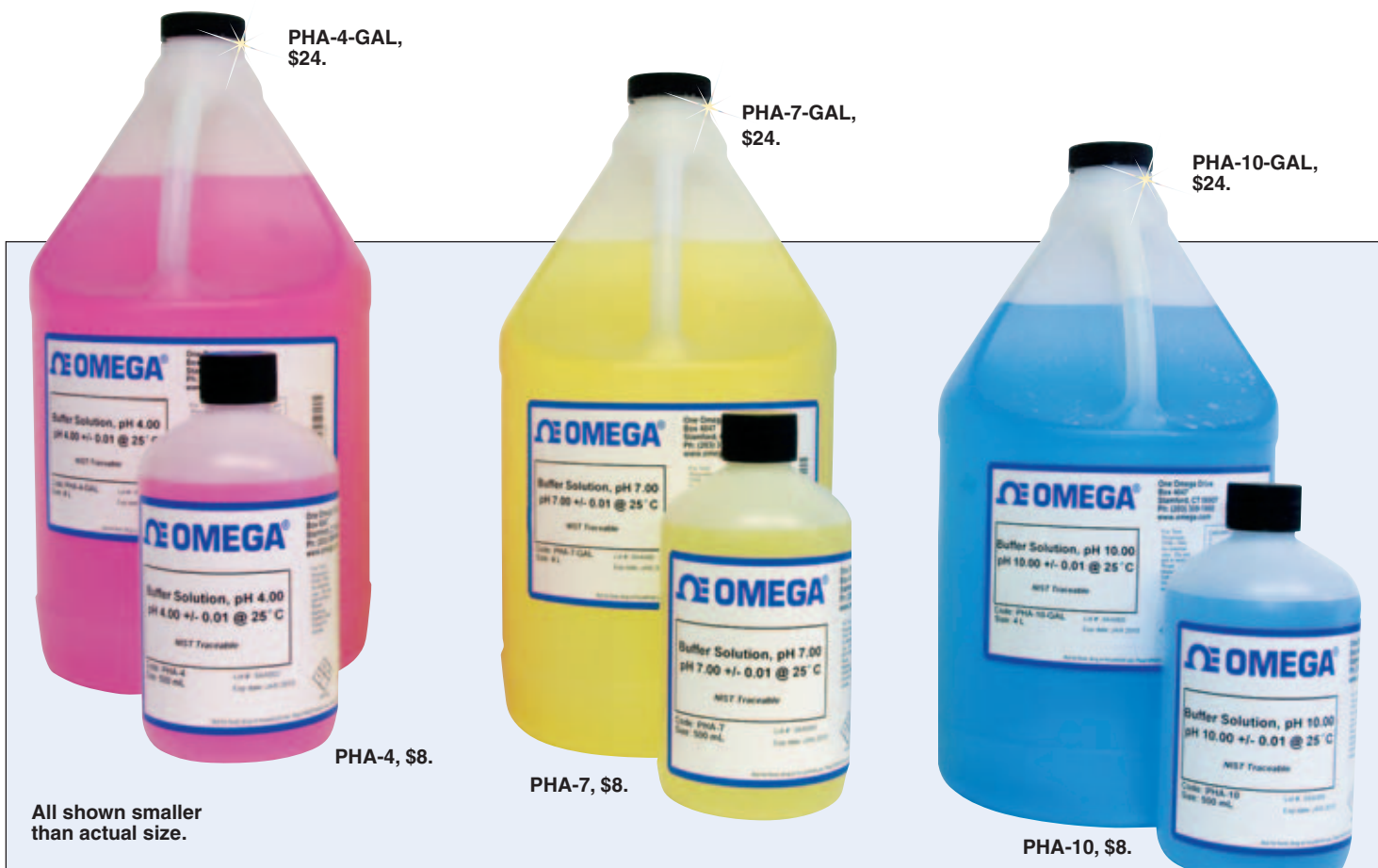

PHA-4-GAL,
\$24.

PHA-7-GAL,
\$24.

PHA-10-GAL,
\$24.

PHA-4, \$8.

PHA-7, \$8.

PHA-10, \$8.

All shown smaller than actual size.

PHA-4
Starts at
\$8



Optional*

- ✓ Deionized Water
- ✓ Pre-Mixed pH Solutions
- ✓ Two Bottle Sizes Available
- ✓ pH Solutions Standardized Against NIST Certified Sample

Formulated to provide precise pH determinations, these buffer solutions which are standardized against NIST-certified reference samples, are ideal for calibrating electrodes and pH meters. The buffers are color-coded to avoid error and accurate to within ± 0.02 pH at 25°C (77°F). Each buffer contains a preservative/mold inhibitor and a shrink-sealed cap to prevent contamination and leakage. Temperature compensation charts are included with each buffer solution.



PHAB-PH, \$20,
5 each 4, 7 and
10 buffer packs
with 5 deionized
water packs.
Shown smaller
than actual size.

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)		
Model No.	Price	Description
PHA-4	\$8	4.00 pH buffer solution 500 mL (1 pint) bottle
PHA-4-GAL	24	4.00 pH buffer solution 4 L (1 gal) bottle
PHA-7	8	7.00 pH buffer solution 500 mL (1 pint) bottle
PHA-7-GAL	24	7.00 pH buffer solution 4 L (1 gal) bottle
PHA-10	8	10.00 pH buffer solution 500 mL (1 pint) bottle
PHA-10-GAL	24	10.00 pH buffer solution 4 L (1 gal) bottle
PHA-DI	8	Deionized water 500 mL (1 pint) bottle
PHA-DI-GAL	24	Deionized water 4 L (1 gal) bottle
PHAB-DI	20	20 single use deionized water packets
PHAB-PH	20	5 each 4, 7 and 10 buffer packs with 5 deionized water packs
CAL-PH*	25	NIST certificate

* For NIST certificate of conformance, add suffix "-NIST" to model number and add an additional line item, **CAL-PH, \$25** per order. NIST certificate available on pH buffers only.

Ordering Examples: **PHA-7-GAL, 7.00 pH buffer solution 1 gallon bottle, \$24.**
PHA-7, 7.00 buffer solution, 1 pt bottle, \$8.

Order Online
omega.com[®]
Over 100,000 Products Available!

To download information and to order pH Field and Lab Electrode products online, visit **omega.com**



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters