




pH Benchtop Meter with RS232 Communications

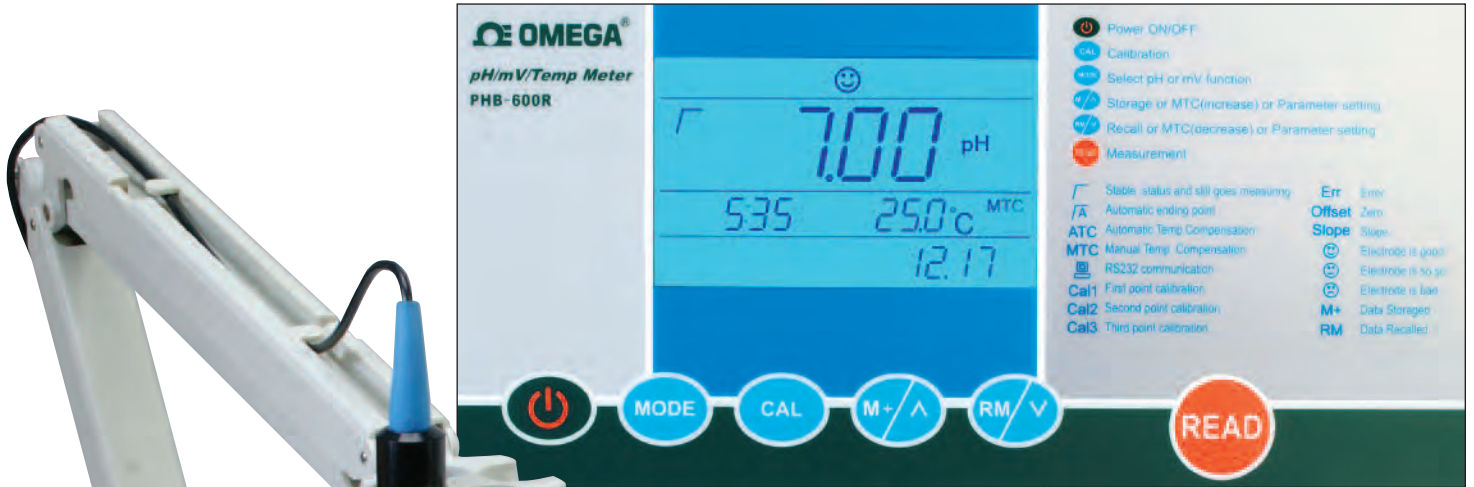

The PHB-600R features a front panel with user-friendly keys with descriptive icons.



PHB-600R, \$570, with pH electrode, temperature probe, 2 buffer solutions and electrode holder (all included), shown smaller than actual size.



PHB-600R
\$570




- ✓ Microprocessor-Based Design
- ✓ Simultaneous Display of pH and Temperature
- ✓ °C/°F Switchable

- ✓ Automatic or Manual Temperature Compensation
- ✓ Stores Up to 64 Readings, Downloadable to a PC via the RS232 Interface

With its built-in microprocessor, the PHB-600R precisely measures pH and mV in water solutions. This makes it suitable for laboratory, industrial, and manufacturing applications.



PHB-60R Back View.

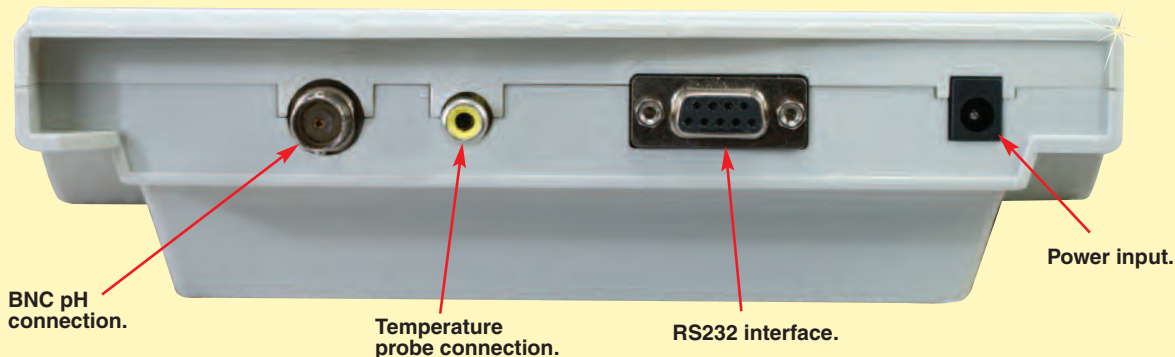

Specifications

Accuracy/Range/Resolution:

Measurement	Range	Resolution	Accuracy
pH	0 to 14	0.01	0.01
mV	±2000	1	1
Temp (°F)	23 to 221	0.1	0.2
Temp (°C)	-5 to -105	0.1	0.1

Temp Compensation: ATC 0 to 100°C (32 to 212°F)

Storage Capacity: 64 readings

Communications: RS232 interface

RS232 Connection: 9-pin sub-D connector

Software: Windows compatible (included)

Power: 110 to 9 Vac adaptor (included)

Dimensions: 200 L x 160 W x 65 mm D (7.8 x 6.3 x 2.6")

Weight: 650 g (1.4 lb)

Operating Environment: 0 to 35°C (32 to 95°F); <85% RH

pH Connection: BNC



Communications cable and software included.

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model No.	Price	Description
PHB-600R	\$570	pH/mV/temp benchtop meter
PHAT-600	54	Replacement temperature probe
PHE-1311	57	General purpose pH laboratory electrode
PHE-1411	70	Double-junction pH laboratory electrode
PHE-2721	81	Double-junction glass pH electrode
PHA-4	8	4.00 pH buffer solution 500 ml (1 pint) bottle
PHA-7	8	7.00 pH buffer solution 500 ml (1 pint) bottle
PHA-10	8	10.00 pH buffer solution 500 ml (1 pint) bottle

Comes complete with pH electrode, temperature probe, 2 buffer solutions of pH 4 and 7, electrode holder, Windows software, communications cable, AC adaptor and operator's manual.

Ordering Example: PHB-600R, pH benchtop meter, \$570.

Recommended Reference Book: Rules of Thumb for Chemical Engineers, CM-4448, \$100, See Section Y for Additional Books





UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters