


# LOW COST pH AND ORP POCKET TESTERS

BB  
pH

- ✓ Water-Resistant
- ✓ Automatic Calibration
- ✓ Automatic Temperature Compensation
- ✓ Longed Battery Life



PHH-8X  
**\$50**

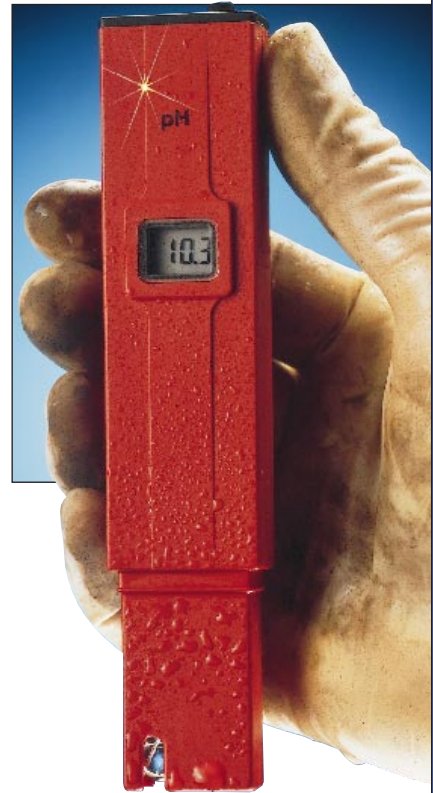

## SPECIFICATIONS

**Range:** 0.0 to 14.0 pH  
**Resolution:** 0.1 pH  
**Accuracy:** ±0.1 pH  
**Calibration:** Automatic 1 or 2 point  
**Temperature Compensation:** Automatic 0 to 50°C (32 to 122° F)  
**Environment:** 0 to 50°C (32 to 122° F), 100% RH  
**Battery Type/Life:** 4 x 1.4 V/700 hours continuous use  
**Dimensions:** 150 x 30 x 24 mm (5.9 x 1.2 x 0.9")  
**Weight:** 85 g (3 oz)

The PHH-8X pH tester is ideal for checking pH in swimming pools, fish farms, electroplating baths, wastewater, and other applications where high humidity and condensation are present. It is supplied with a rugged, integral pH electrode in a protective housing. The large liquid crystal display indicates when a stable reading has been reached. Automatic 1 or 2 point calibration and automatic temperature compensation simplify operation. An Auto Shut-Off feature helps prolong battery life by turning off the tester after 10 minutes of non-use.

### To Order (Specify Model Number)

| Model No. | Price | Description               |
|-----------|-------|---------------------------|
| PHH-8X    | \$50  | Water resistant pH tester |

# REDOX POTENTIAL TESTERS

- ✓ Fast Response
- ✓ Excellent Reproducibility
- ✓ Long Battery Life

ORP-1  
**\$71**



## SPECIFICATIONS

**Range:** ±999 mV  
**Resolution:** 1 mV  
**Accuracy:** ±5 mV  
**Environment:** 0 to 50°C (32 to 122°F), 95% RH  
**Battery Type / Life:** 4 x 1.4 V/700 hours continuous use  
**Dimensions:** 150 x 30 x 24 mm (5.9 x 1.2 x 0.9")  
**Weight:** 85 g (3 oz)

An ideal companion to the PHH-8X pH tester, the ORP-1 REDOX potential tester offers hand held convenience for measuring oxidation reduction potential in a wide variety of sample types. The built-in platinum electrode gives fast response and excellent repeatability. Typical applications include plating baths, wastewater, agriculture and aquariums.

### To Order (Specify Model Number)

| Model No. | Price | Description            |
|-----------|-------|------------------------|
| ORP-1     | \$71  | REDOX potential tester |

BB-6



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters