

# HANDHELD/BENCHTOP HEAT GUNS

148000 Series  
Starts at

**\$111**



## LIGHTWEIGHT HEAT GUN, 148002: \$111

Lightweight (only 28 oz) whisper-quiet, heavy-duty motor allows for fatigue-free use hour after hour.

Each heat gun includes a bench-stand, a silver 343°C (650°F) heating element and a deflector adaptor for shrink tubing. Flowrate is 3.8 CFM.

**Replacement Element:**  
148004, \$24

## HEAT GUN, 148003: \$209


This unit features an exclusive electronic temperature control which enables the user to select the temperature desired for each job and lock it in. A rubber-padded, non-slip, adjustable base allows the heat gun to be used in many benchtop operating positions. Flowrate is 17 CFM.

**Replacement Element:**  
148023, \$24

## STANDARD HEAT GUN, 148001: \$146

Adjustable air intake control and a powerful high speed universal motor allow for control of volume heat, hour after hour. Double-jacketed heater housing protects heating element and sturdy die-cast aluminum housing is rugged to protect motor assembly from hard knocks. A non-slip rubber-backed base permits rotation of heat gun for use in any position on your workbench. Flowrate is 23 CFM.

**Replacement Element:**  
148004, \$24

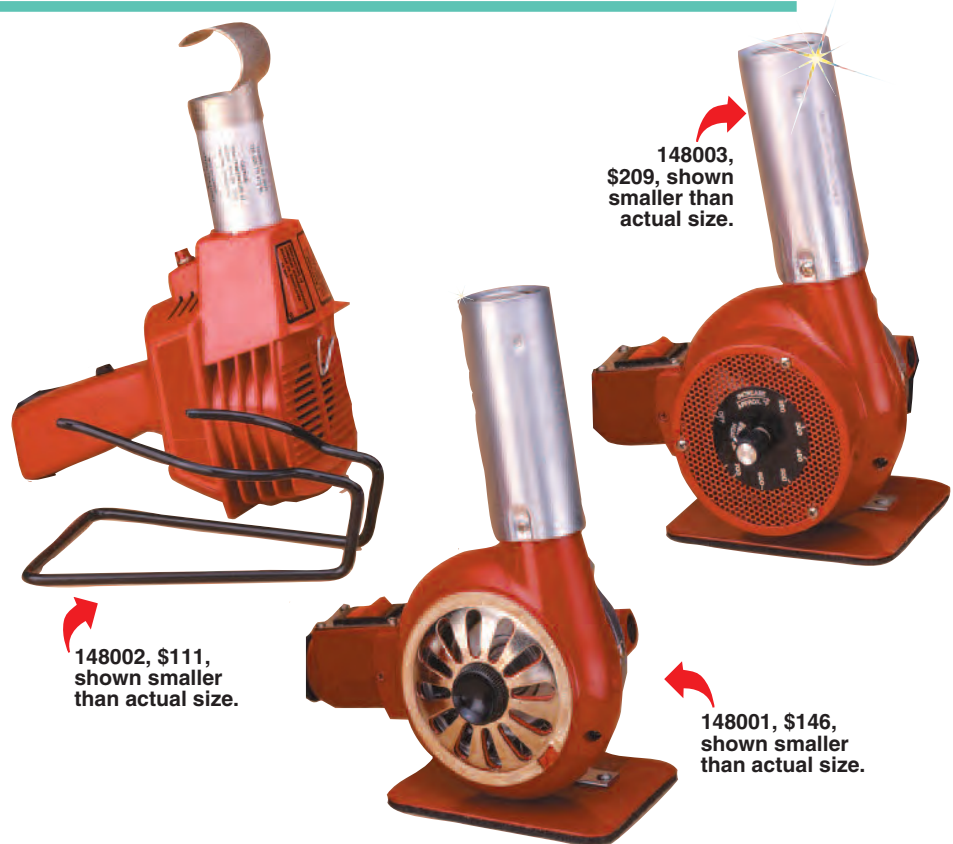

**AVAILABLE FOR FAST DELIVERY!**

### To Order (Specify Model Number)

Model No.	Price	Volts	Amps	Max Temp °C (°F)	Weight kg (lb)
148001	\$146	120	14	260 to 399 (500 to 750)	1.7 (3.75)
148002	111	120	4	343 (650)	0.8 (1.75)
148003	209	120	14	538 (1000)	1.7 (3.75)

*Ordering Example: 148001, 120V, 14 A handheld benchtop heat gun, \$146.*

### Accessories

Model No.	Description	Price
148005	Shrink tubing attachment for tubing up to 3/4" OD	\$14
148006	Shrink tubing attachment for tubing up to 2" OD	14
148008	Pinpoint heat attachment directs 1/4" heat	14
148009	Extra-wide (8") for shrink tubing up to 3/4" OD	41

### Heating Elements

Model No.	Color	Temperature °C (°F)	Volts	Watts	Price
148013	Blue	260 (500)	120	340	\$27
148014	Silver	343 (650)	120	475	27
148015	Black	426 (800)	120	525	27



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters