





PORTABLE THERMOCOUPLE TEMPERATURE CONTROLLER

CN-TOT Starts at
\$239



- ✓ Portable, Plug and Play
- ✓ Easy-to-Use Digital On/Off Controller
- ✓ Type J Thermocouple Mini Connector Input
- ✓ 5°C (9°F) Differential
- ✓ Audible Alarm
- ✓ Operating Exposure Temperature -10 to 55°C (-14 to 131°F)
- ✓ 1.8 m (6') Input Power Cord with Standard Plug (120 Vac, NEMA 5 to 15; 240 Vac, NEMA 6 to 15)
- ✓ Output Receptacle (120 Vac, NEMA 5 to 15R; 240 Vac, NEMA 6 to 15R)
- ✓ Average Accuracy of ±1% FS
- ✓ 120 or 240 Vac
- ✓ 15 A Capacity
- ✓ For Indoor Use

The CN-TOT portable thermocouple temperature controller is designed for indoor, general purpose use. It can control the temperature of small tanks, drums, pipes, intermediate bulk containers (IBCs), and other objects that require automatic control.

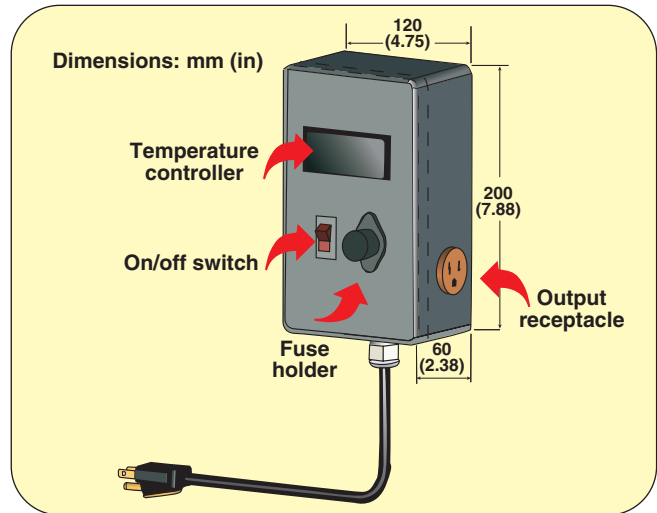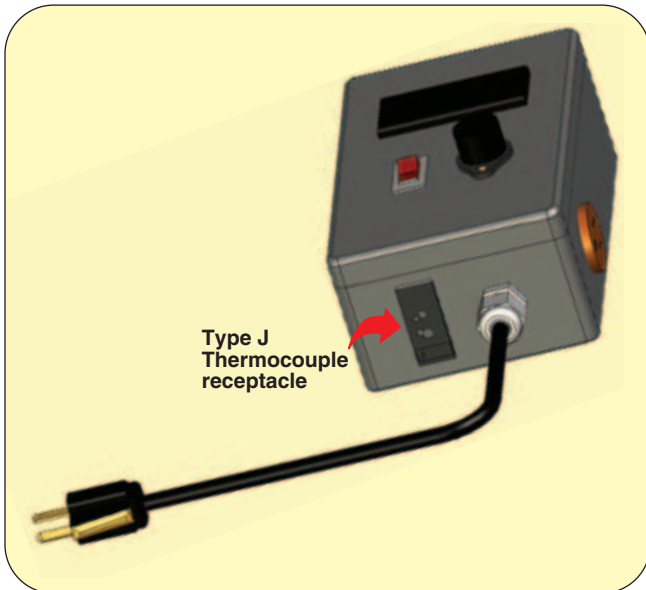

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model No.	Price	Description
CN-TOT-A-175JF-120V	\$239	Controller, 10 to 79°C (50 to 175°F) range, 120V, 15 A
CN-TOT-A-175JF-240V	239	Controller, 10 to 79°C (50 to 175°F) range, 240V, 15 A
OP-4	15	Reference Book: Thermocouple Elements

Ordering Example: CN-TOT-A-175JF-120V, thermocouple temperature controller, 10 to 79°C (50 to 175°F) range, 120V, 15 A, \$239.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters