



# HIGH PERFORMANCE FAN HEATER FOR PANEL, DIN RAIL OR FOOT-MOUNT

CR030/CR130 Series  
Starts at  
**\$209**



- ✓ Compact DIN Rail, Panel Mount or Foot-Mounted Fan Heater
- ✓ Maintains Minimum Operating Temperatures in Enclosures
- ✓ Helps to Prevent Failure of Electronic Components Caused by Condensation and Corrosion
- ✓ Built-In Overheat Protection
- ✓ Integrated Adjustable Thermostat
- ✓ Double Insulated Plastic Housing



CR030599, \$209, shown smaller than actual size.



CR130599, \$220, shown smaller than actual size.

## Specifications

**Heating Element:** High performance cartridge heater

**Heat Sink:** Extruded aluminum profile

**Overheat Protection:** Built-in temperature limiter

**Axial Fan (Ball Bearing):** Service life 50,000h @ 25°C (77°F)

**Air Flow, Free Blowing:** 160 m<sup>3</sup>/h (94 cfm)

**Connection:** 2-pole terminal AWG 16 max (1.5 mm<sup>2</sup>) with strain relief, clamping torque 0.8 Nm max

### Mounting:

**CR030:** M5 screws (not included)

**CR130:** Clip for 35 mm DIN rail, EN 60 715 or M6 screws (not included)

**Position:** Preferably horizontal

**Wiring Compartment:** Plastic, UL94V-0, black

### Dimensions:

**CR030:** 168 x 145 x 99 mm (6.6 x 5.7 x 3.9")

**CR130:** 182 x 160 x 99 mm (7.2 x 6.3 x 3.9")



**Weight:** 1.4 kg (3.1 lb)

**Operating Temperature:** 0 to 60°C (32 to 140°F)

**Storage Temperature:** -45 to 70°C (-49 to 158°F)

**Protection Class:** II (double isolated)

**Protection Type:** NEMA 2 (IP20)

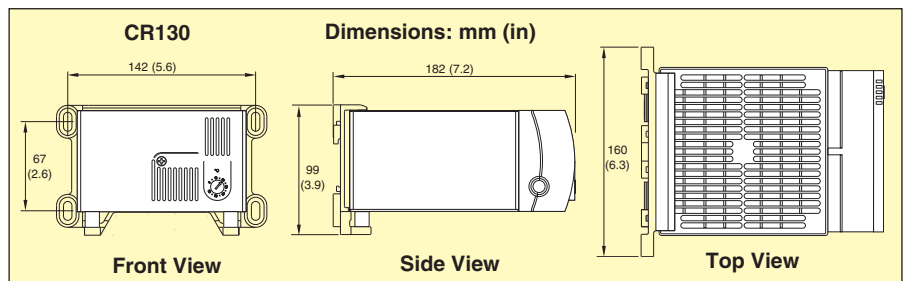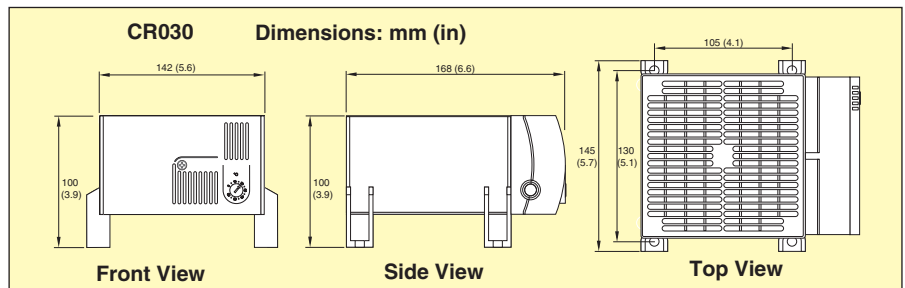

**AVAILABLE FOR FAST DELIVERY!**

## To Order (Specify Model Number)

Model No.	Price	Description
CR030599	\$209	Fan heaters, 950 W, 120 Vac with adjustable thermostat 0 to 60°C (32 to 140°F), foot mount
CR130599	220	Fan heaters, 950 W, 120 Vac with adjustable thermostat 0 to 60°C (32 to 140°F), DIN or panel mount
XBANS3575P	9	DIN rail 35 x 7.5 mm x 2 m (1.4 x 0.30" x 6') slotted

Comes complete with operator's manual.

**Ordering Examples:** CR030599, foot-mounted fan heater, \$209.

CR130599, DIN or panel mounted fan heater, \$220.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters