

PRESSURE VOLUME CONTROLLERS

**AVC-1000
and AVC-3000**
Vacuum to 1000 or
Vacuum to 3000 psi


Starts at
\$1900




OMEGA® pressure volume controllers provide an easy means of rapidly and accurately adjusting the pressure in a closed system to within 0.00025 psi. They can be used with digital pressure gauges, dial gauges, transducers, pressure switches, air deadweight testers, manometers, and similar devices. OMEGA® pneumatic controllers are available for use with pressures up to 3000 psi.

Engineered to provide superior performance and safety, these devices incorporate a unique pressure balance valve. This valve is opened during initial system pressurization. When opened, the valve provides equal pressure to both sides of the piston assembly (see Figure 1). After the system has been pressurized, the valve is closed. Once the valve is closed, a change in piston position will change the pressure within the system. Simply turning the large pressure adjust knob repositions the piston to increase or decrease the pressure.

Equalization of pressure on both sides of the piston ensures ease of pressure setting. In addition, the valve performs a safety function. The balance valve will open automatically if an excessive pressure differential is generated across the piston. In essence, the valve serves as a safety relief valve and protects the controller from damage due to excessive pressure differentials within the unit.

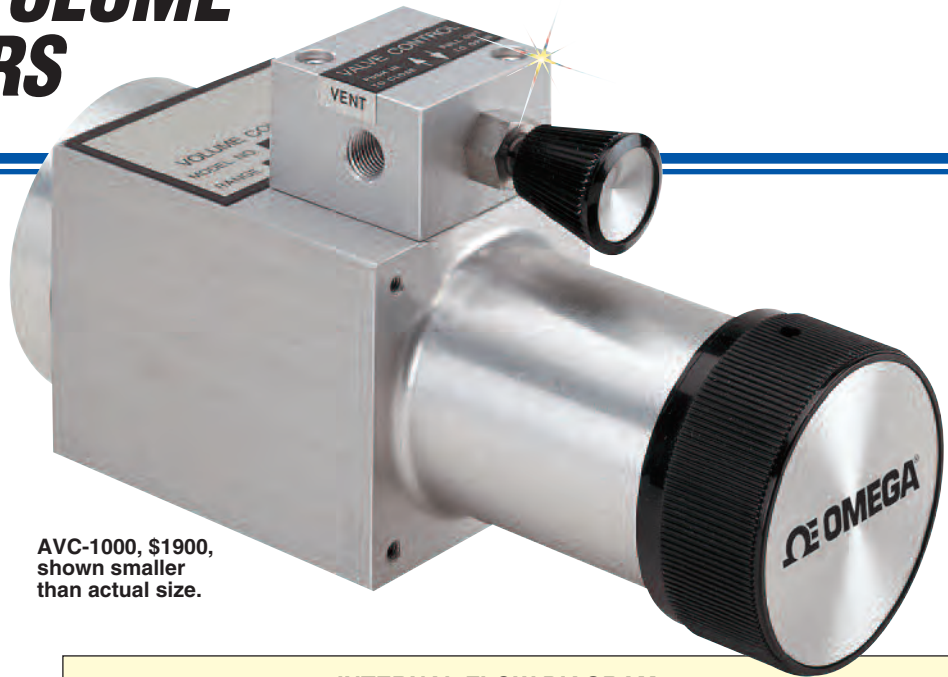

AVC-1000, \$1900, shown smaller than actual size.

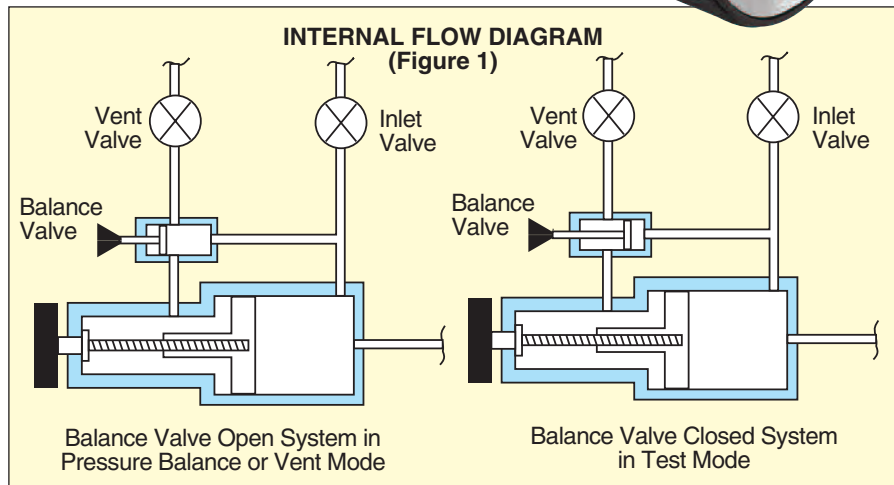

AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)		
MODEL NO.	PRICE	
AVC-1000	\$1900	
AVC-3000	2245	
Specifications	AVC-1000	AVC-3000
Range (psi)	Vacuum to 1000	Vacuum to 3000
Proof (psi)	2000	6000
Burst (psi)	6000 min	12,000 min
Resolution (psi)	0.00025	0.0005
Volume Change (Cubic Inches)	57.35 mL (3.5 cubic in)	40.97 (2.5 cubic in)
Mechanical Rotation (Total Turns)	31	61
Connection (Female)	1/8 NPT	1/8 NPT
Operating Temp Range	-18 to 49°C (20 to 120°F)	
Construction	Aluminum body, stainless steel, brass, PTFE, Acetal and Buna-N	

Comes complete with operator's manual.

Ordering Example: AVC-1000, pressure volume controller, vacuum to 1000 psig, \$1900.

Recommended Reference Book: Industrial Control Systems, MS-1785, \$80.
Visit omega.com/bobi for Additional Books





UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters