

# 483 mm (19") Jack Panels


## Miniature Connectors With Anodized Panels

Rugged 3.1 mm (1/8") Thick Panels

19MJP Series

Starts at

**\$47<sup>50</sup>**

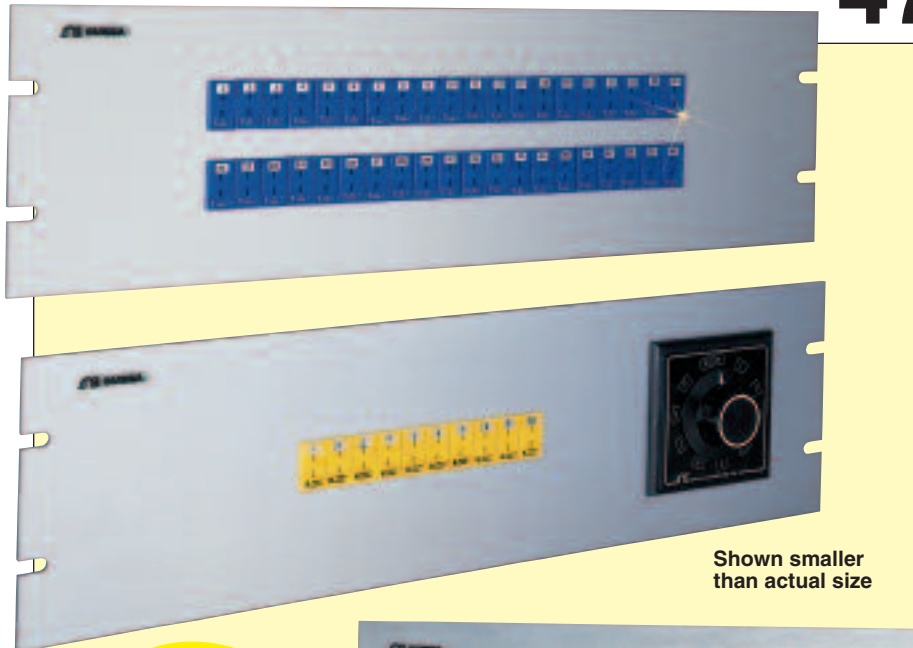

Shown smaller than actual size

**Dust Caps  
Included Free With  
Each Panel**

**MOST POPULAR  
MODELS HIGHLIGHTED!**

Model No. ANSI Color Code	Price*	Total No. of Jacks	Switch Cutout	Meter Cutout
19MJP1-10-(* )	\$47.50	10	-	-
19MJP1-12-(* )	49.30	12	-	-
19MJP1-18-(* )	61.45	18	-	-
19MJP1-20-(* )	65.50	20	-	-
19MJP1-30-(* )	82.38	30	-	-
19MJP2-32-(* )	91.20	32	-	-
19MJP2-40-(* )	106.50	40	-	-
19MJP1-10-(* )-OSW	57.50	10	76 mm (3")	-
19MJP1-20-(* )-OSW	75.50	20	76 mm (3")	-
19MJP2-40-(* )-OSW	116.50	40	127 mm (5")	-
19MJP3-30-(* )-OSW	102.38	30	127 mm (5")	-
19MJP3-40-(* )-OSW	121.50	40	127 mm (5")	-
19MJP4-40-(* )-OSW	121.50	40	127 mm (5")	-
19MJP1-10-(* )-OSW-MTR	62.50	10	76 mm (3")	Y
19MJP2-20-(* )-OSW-MTR	80.50	20	76 mm (3")	Y
19MJP3-30-(* )-OSW-MTR	107.38	30	127 mm (5")	Y
19MJP4-40-(* )-OSW-MTR	126.50	40	127 mm (5")	Y

**Note:** Panels with switches and/or meters are not supplied wired. Wiring charge is \$5 per circuit. Consult factory for details.

\*Insert J, K, T, E, R, S, N, G, C, D or U calibration code. Dust caps included.

Shipped unassembled.

**Ordering Example:** 19MJP3-40-K-OSW, 483 mm (19") long panel with 40 Type K mini panel jack connectors organized in 3 rows and a cut out for an OMEGA selector switch, \$121.50.


### 483 mm (19") Plain Panel Jacks

No. of Rows	Panel Height	Max. No. of Jacks
1	89 mm (3 1/2")	30
2	89 mm (3 1/2")	60
3	133 mm (5 1/4")	90
4	178 mm (7")	120

### 483 mm (19") Jack Panels with Switch Cutout

No. of Rows	Panel Height	Switch Size	Max. No. of Jacks
1	133 mm (5 1/4")	76 mm (3")	20
2	133 mm (5 1/4")	76 mm (3")	40
2	178 mm (7")	127 mm (5")	40
3	178 mm (7")	127 mm (5")	60
4	178 mm (7")	127 mm (5")	80

**Note:** When a switch is ordered with a panel, installation is included at no extra cost.

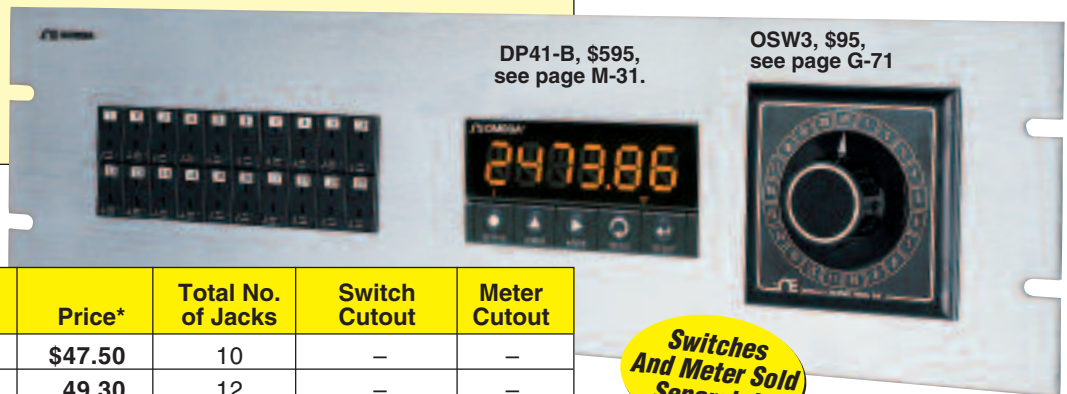

DP41-B, \$595,  
see page M-31.

OSW3, \$95,  
see page G-71

**Switches  
And Meter Sold  
Separately**

### 483 mm (19") Jack Panels with Switch and Meter Cutouts

No. of Rows	Panel Height (mm/in)	Switch Size (mm/in)	Max. No. of Jacks
1	133 (5 1/4")	76 (3")	10
2	133 (5 1/4")	76 (3")	20
3	178 (7")	127 (5")	30
4	178 (7")	127 (5")	40

**Note:** a 45 x 92 mm (1 7/8" DIN) meter cutout is supplied unless otherwise specified.

**Consult Sales Department for  
information on custom,  
color-coded anodized panels.**



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters