

483 mm (19") Universal Jack Panels

Accepts **Standard** and **Miniature** Connectors



ANSI color code shown
To order IEC color code see pg. A-9


483 mm (19") Plain Jack Panels

No. of Rows	Panel Height	Max. No. of Jacks
1	89 mm (3½")	22
2	133 mm (5¼")	44
3	178 mm (7")	66
4	222 mm (8¾")	88

483 mm (19") Jack Panels with Switch Cutout

No. of Rows	Panel Height	Switch Size	Max. No. of Jacks
1	133 mm (5¼")	76 mm (3")	15
2	133 mm (5¼")	76 mm (3")	30
2	178 mm (7")	127 mm (5")	30
3	178 mm (7")	127 mm (5")	45
4	222 mm (8¾")	127 mm (5")	60

Note: When a switch is ordered with a panel, installation is included at no extra charge, add suffix **"-MTG"** to model number of switch or meter. Panels with switches and/or meters are not supplied wired. Wiring charge is \$5 per circuit. Consult factory for details.

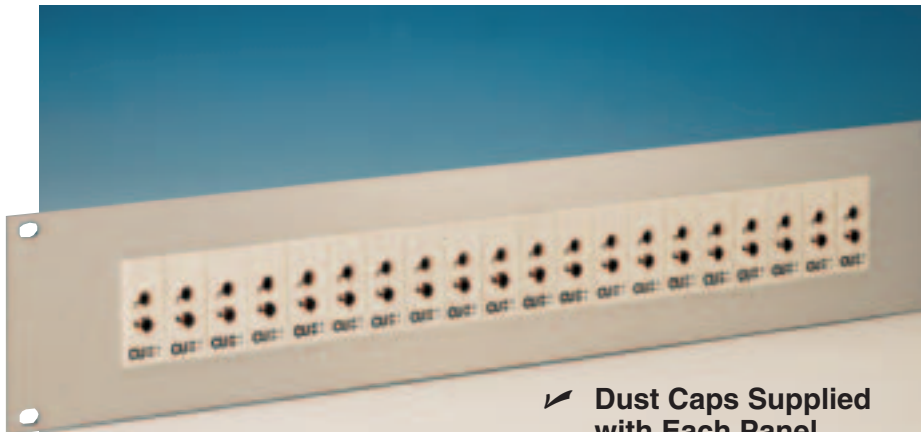

PATENTED

Covered by U.S and International patents and pending applications

✓ Dust Caps Supplied with Each Panel

Consult Sales Department for information on custom, color-coded anodized panels.



OSW3, \$95, see page G-73

DP460 Series, \$249, see page M-47

Shown smaller than actual size

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

Model No. ANSI Color Code	Price	Total No. of Jacks	Switch Cutout	Meter Cutout
19UJP1-10-(*)	\$77.50	10	—	—
19UJP1-20-(*)	119.50	20	—	—
19UJP2-20-(*)	124.50	20	—	—
19UJP2-28-(*)	154.95	28	—	—
19UJP2-30-(*)	163.88	30	—	—
19UJP3-30-(*)	168.88	30	—	—
19UJP4-40-(*)	218.50	40	—	—
19UJP1-10-(*)-OSW	87.50	10	76 mm (3")	—
19UJP3-30-(*)-OSW	168.88	30	127 mm (5")	—
19UJP4-40-(*)-OSW	223.50	40	127 mm (5")	—
19UJP1-10-(*)-OSW-MTR	92.50	10	76 mm (3")	Y
19UJP3-30-(*)-OSW-MTR	178.88	30	127 mm (5")	Y
19UJP4-40-(*)-OSW-MTR	223.50	40	127 mm (5")	Y

*Insert calibration code in model number: J, K, T, E, R, S or U.
Ordering Example: 19UJP1-10 (including dust caps), \$77.50.

483 mm (19") Jack Panels with Switch and Meter Cutouts

No. of Rows	Panel Height (mm/in)	Switch Size (mm/in)	Max. No. of Jacks
1	133 (5¼")	76 (3")	10
2	133 (5¼")	76 (3")	20
2	178 (7")	127 (5")	20
3	222 (8¾")	127 (5")	30
4	222 (8¾")	127 (5")	40

Note: A ½ DIN (45 x 92 mm) meter cutout is supplied unless otherwise specified.

Extra Supply of our Patented Design Dust Caps SPJ-CAP-12 \$6/pkg of 12





UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters