

Handheld Digital Thermometers

HH508
\$115



- NEMA 4X Dustproof
- Water/Splash Resistant
- Warning Beeper with Hi/Lo Setting, Time Setting
- Clock and Elapsed Time
- 0.1° Resolution
- Differential Thermocouple Input
- Stated Accuracy @ 23 ± 5°C < 75% RH
- Battery Life: 200 Hours
- Dimensions: 192 H x 91 W x 53 mm D (7.6 x 3.6 x 2.2")
- Weight: Approx 255 g (9 oz)

For Complete Product Information Visit omega.com/hh508_509


Probes sold separately. Please see Section A for details.

Features

- Data Hold
- Max/Min
- Relative
- Hi/Lo Limits with Beeper Warning
- T1-T2 (HH509 Only)
- Auto Power Off

Specifications

Display Type: Backlit LCD
Number of Digits: 1999
Probe (Type): K/J/E/T/S
Input Channels
 HH508: 1
 HH509: 2
Temperature Range: -210 to 1767°C (-346 to 1999°F)
Resolution: 0.1°/1°
Power: One 9V battery (included)
Basic Accuracy: 0.1% + 1°C

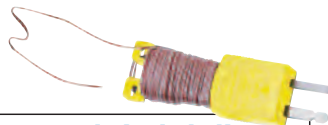

Free Thermocouple Included!

These models include a free 1 m (40") Type K insulated beaded wire thermocouple with subminiature connector and wire spool caddy (1 per channel). **Order a Spare! Model No. SC-GG-K-30-36, \$15.**



OMEGACARESM extended warranty program is available for models shown on this page. Ask your sales representative for full details when placing an order. OMEGACARESM covers parts, labor and equivalent loaners.

HH508, \$115.



AVAILABLE FOR FAST DELIVERY!

To Order (Specify Model Number)

Model No.	Price	Description
HH508	\$115	Digital thermometer
HH509	125	Digital thermometer, dual
HH509R	155	Digital thermometer, dual, with RS232
SC-GG-K-30-36	15	Spare Type K beaded thermocouple (1 m long)
KTSS-HH	29	150 mm (6") long, 3 mm (1/8") dia. stainless steel Type K probe with 300 mm (12") retractable cable [expands to 1.2 m (48")] terminating with male subminiature connector
HH-NIST†	55	NIST-traceable calibration, no points
CAL-3-HH†	85	NIST-traceable calibration with points
MN1604	3	Spare 9V alkaline battery
SC-HH500	12	Soft carrying case

Ordering Examples: HH508, digital thermometer, \$115.

HH509R, dual input digital thermometer with RS232, \$155. OCW-3, OMEGACARESM extends standard 1-year warranty to a total of 4 years (\$38), \$155 + 38 = 193.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters