

# Economical Handheld Thermometer With Magnet Hanger

HH74K  
**\$59**



Standard  
No Points

- ✓ Lightweight Design
- ✓ Pocket Hook and Magnet Hanger
- ✓ ADJ Thermocouple Offset Function
- ✓ Max/Data Hold Function
- ✓ Auto Power-Off Function Can be Disabled
- ✓ Battery Life 300 Hours Typical Use
- ✓ °C or °F Switchable
- ✓ NIST-Traceable Certificate of Calibration (No Points)

## Specifications

**Display:** 3½ digit LCD

**Low-Battery Indication:**

The "E" is displayed

**Measurement Rate:** 2.5 times per second

**Operating Environment:** 0 to 50°C (32 to 122°F) @ <70% RH

**Storage Environment:** -20 to 60°C (-4 to 140°F), 0 to 80% RH with battery removed from meter

**Stated Accuracy:** 23 ±5°C (73 ± 9°F), <75% RH

**Battery:** Three 1.5V "AAA" (included)

**Battery Life:** 300 hours, typical use



HH74K, \$59, shown with optional SA1-K-SC, self-adhesive thermocouple, \$75 for package of 5. Visit [omega.com/sa1](http://omega.com/sa1)

**POCKET PAL™**

## OMEGAETTE™

### Temperature:

**Range:** -100 to 850°C (-148 to 1562°F) Type K (CHROMEGA®-ALOMEGA®)

**Resolution:** 1°C or 1°F, 0.1°C or 0.1°F

### Accuracy (Does Not Include Probe):

18 to 28°C (64 to 82°F) ambient  
±(0.3% rdg + 1°C) on °C ranges  
±(0.3% rdg + 2°F) on °F ranges

| Resolution | Range                          |
|------------|--------------------------------|
| 0.1°C      | -59.9 to 199.9°C               |
| 1°C        | -100 to -60°C<br>200 to 850°C  |
| 0.1°F      | -59.9 to 199.9°F               |
| 1°F        | -148 to -60°F<br>200 to 1562°F |

**Dimensions:** 148 H x 48 W x 24 mm D (5.8 x 1.9 x 0.94")

**Weight:** Approximately 74 g (2.6 oz) with battery

**Connector:** SMP


### Applications

- ✓ Greenhouses
- ✓ Office Environment
- ✓ Environmental Studies
- ✓ Labs
- ✓ Workshops
- ✓ Art Galleries/Museums
- ✓ Weather Monitoring
- ✓ Department Stores

### Free Thermocouple Included!

HH74K models include a free 1 m (40") Type K insulated beaded wire thermocouple with subminiature connector and wire spool caddy (1 per channel). **Order a Spare!**

**Model No. SC-GG-K-30-36, \$15.**

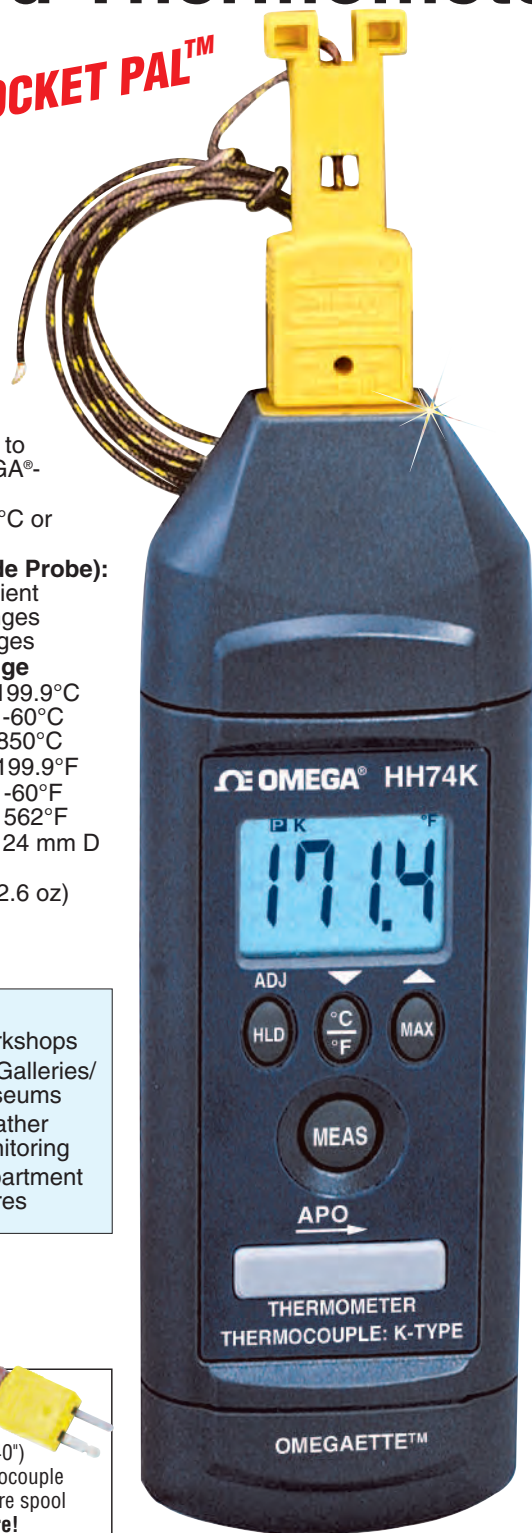

HH74K, \$59, shown actual size.

**AVAILABLE FOR FAST DELIVERY!**

### To Order (Specify Model Number)

| Model No. | Price | Description                                 |
|-----------|-------|---|
| HH74K     | \$59  | Type K thermometer                          |
| SC74      | 10    | Soft carrying case, see pages L-59 and L-60 |

Comes complete with operator's manual, thermocouple, magnet hanger, NIST certificate (no points) and 3 "AAA" batteries.

**Ordering Example:** HH74K, Type K thermometer with magnet hanger, \$59.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters