

OMEGAMETER®

MIX AND MATCH SERIES

DIGITAL MULTIMETERS WITH NON-CONTACT VOLTAGE AUDIBLE BUZZER FEATURE




HHM33
\$29



3½ digit, 1999 Counts Digital Display
DC Volts: 0 to 2 V/20 V/600 V ±1.2%
AC Volts:
 0 to 200 V/600 V/50 to 500 Hz ±2.5%
DC Current: 0 to 200 µA/2 mA/20 mA/
 200 mA/10 A ±2.5%
Resistance: 0 to 200 Ω/2 KΩ/20 KΩ/
 200 KΩ/20 MΩ ±2.0%
Resolution:
 1 mV, 100 mV, 0.1 µA, 0.1 Ω
Battery Test: 1.5 V/9 V ±3.5%
Diode Test
10A Fused
Safety Input Jacks
Safety Test Leads
Overload Protection on All Ranges



Test leads included with all models shown!

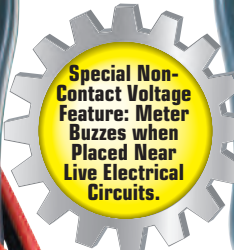

Special Non-Contact Voltage Feature: Meter Buzzes when Placed Near Live Electrical Circuits.



HHM34
\$39

3½ digit, 1999 Counts Digital Display
DC Volts: 0 to 200 mV/2 V/20 V/600 V ±1.2%
AC Volts: 0 to 200 mV/2 V/200 V/600 V/
 50 to 500 Hz ±2.0%
DC Current: 0 to 200 µA/20 mA/200 mA/
 10 A ±1.5%
AC Current: 0 to 200 µA/20 mA/200 mA/
 10 A/50 to 500 Hz ±2.0%
Resistance:
 0 to 200 Ω/2 KΩ/200 KΩ/20 MΩ ±1.5%
Resolution: 100 µV, 0.1 µA, 0.1 Ω
Diode Test
Continuity Test
Non-Contact Voltage Indicator
 Low-tension lines from
 70 to 440Vac 50 to 60 Hz
Data Hold, MAX Hold, 10A Fused,
Safety Input Jacks, Safety Test Leads
Overload Protection on All Ranges



HHM35
\$54

All models shown smaller than actual size.

3200 Counts with Annunciators
Auto Power-Off Function
Auto or Manual Range Selection
Bar Graph Display: 12 time/sec sampling
DC Volts (Auto): 0 to 320 mV/3.2 V/
 32 V/320 V/600 V ±1.2%
AC Volts (Auto): 0 to 3.2 V/32 V/320 V/
 600 V/ 50-200 Hz ±2.0%
DC Current: 0 to 320 µA/3200 µA/
 32 mA/320 mA/10 A ±2.0%
AC Current: 0 to 320 µA/3200 µA/
 32 mA/320 mA/10 A ±2.5%
Resistance: 0 to 320 Ω/3.2 KΩ/320 KΩ/
 3.2 MΩ/30 MΩ ±1.5%
Resolution: 100 µV, 0.1 µA, 0.1 Ω
Diode Test
Continuity Test, Data Hold, 10A Fused,
Safety Input Jacks, Safety Test Leads,
Overload Protection on All Ranges



CHEAPER BY THE DOZEN!
 Purchase any Combination of 12 Units and Save 20%

To Order (Specify Model Number)

AVAILABLE FOR FAST DELIVERY!

| MODEL NO. | PRICE* | DESCRIPTION |
|-----------|--------|--------------------------------------|
| HHM33 | \$29 | Basic DMM |
| HHM34 | 39 | Voltage DMM with non-contact feature |
| HHM35 | 54 | Multifunction DMM |
| HHM-TL | 5 | Spare set of test leads |
| HHM-NIST | 55 | NIST calibration certificate |

* Buy any combination of 12 units at one time and save 20%. Comes with test leads and operator's manual.

Ordering Example: HHM35, multifunction DMM and HHM-TL, spare set of test leads, \$54 + 5 = \$59.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters