

# HIGH TEMPERATURE FURNACE CABLE

## Ceramic-Mica Silica Insulated with Stainless Steel Overbraid

HTCM/HTSM Series Starts at

**\$7**

10' 18 AWG  
HTCM-1NI-618S




- ✓ 700°C (1292°F) Temperature Rating
- ✓ For Use in Non-Flexing Applications
- ✓ Single Stranded, "D" Nickel Conductor
- ✓ Mica Tape Insulation with Ceramic Fiber or Silica
- ✓ Jacket and Stainless Steel Overbraid

OMEGALUX® HTCM/HTSM high temperature lead wire is designed for use in very high temperature applications as a single conductor lead wire. It is recommended for use in areas that are exposed to high temperatures but with a minimum of flexing after installation. Such applications include ovens, kilns or furnaces. The stainless steel outer braid provides mechanical protection.

Discount Schedule	
25 to 99 ft. ....	5%
100 to 249 ft. ....	7%
250 and up .....	10%

**CAUTION AND WARNING!**  
Fire and electrical shock may result if products are used improperly or installed or used by nonqualified personnel.

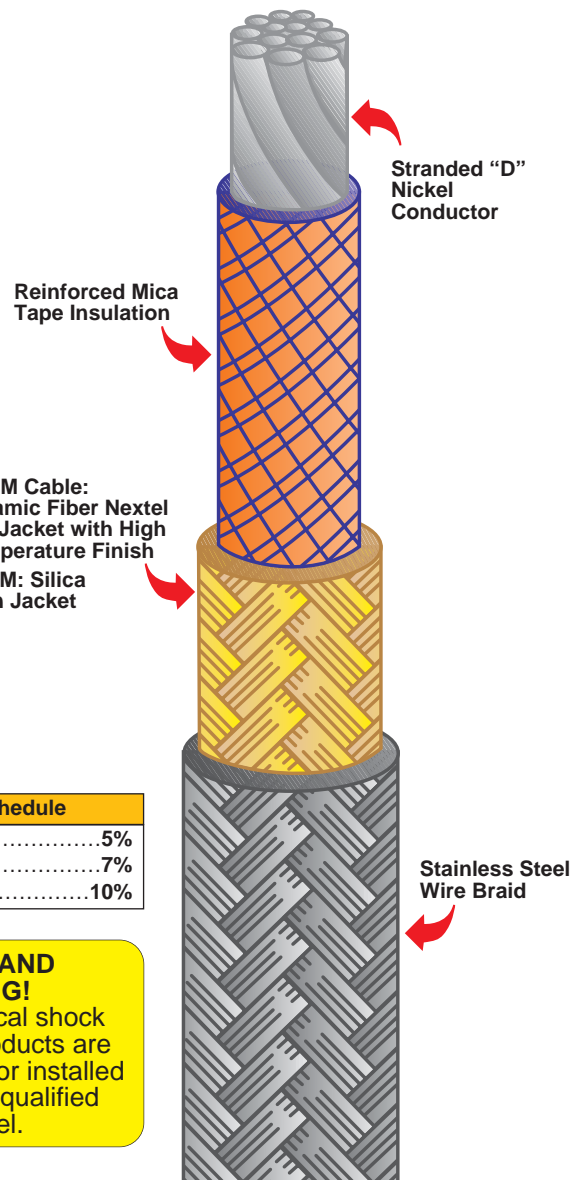

  MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)							
Wire Gage	Description	Model No.	Price per foot	Type Stranded	Volts	Wt. per Nominal OD mm (in )	1000' kg/300 m (lb/1000')
18	Ceramic Fiber	<b>HTCM-1NI-618S</b>	<b>\$7.00</b>	16 x 30	300	3.4 (0.14)	12.2 (27)
16	Ceramic Fiber	<b>HTCM-1NI-616S</b>	<b>7.50</b>	26 x 30	300	3.7 (0.15)	15.4 (34)
14	Ceramic Fiber	<b>HTCM-1NI-614S</b>	<b>8.50</b>	41 x 30	300	4.1 (0.16)	19.1 (42)
12	Ceramic Fiber	<b>HTCM-1NI-612S</b>	<b>11.00</b>	65 x 30	300	4.5 (0.18)	24.5 (54)
10	Ceramic Fiber	<b>HTCM-1NI-610S</b>	<b>13.50</b>	105 x 30	300	5.6 (0.22)	32.7 (72)
18	Ceramic Fiber	<b>HTSM-1NI-618S</b>	<b>\$7.00</b>	19 x 30	300	3.4 (0.14)	12.2 (27)
16	Ceramic Fiber	<b>HTSM-1NI-616S</b>	<b>7.50</b>	26 x 30	300	3.7 (0.15)	15.4 (34)
14	Ceramic Fiber	<b>HTSM-1NI-614S</b>	<b>8.50</b>	41 x 30	300	4.1 (0.16)	19.1 (42)
12	Ceramic Fiber	<b>HTSM-1NI-612S</b>	<b>11.00</b>	65 x 30	300	4.5 (0.18)	24.5 (54)
10	Ceramic Fiber	<b>HTSM-1NI-610S</b>	<b>13.50</b>	105 x 30	300	5.6 (0.22)	32.7 (72)

Minimum order is 10'.

Note: UL listing and CSA certification are not available for HTCM/HTSM series wire.

Ordering Example: HTCM-1NI-616S, a 50' spool of 16 gage stranded heater hook-up wire, \$7.50 x 50 = \$375 (less 5% discount) = \$356.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters