


Silicone Rubber Insulated High Temperature Heater Hook-Up Wire

HTRG Series
Starts at
\$0.45
Per Foot



- ✓ 200°C (392°F) Temperature Rating
- ✓ UL and CSA Certified*
- ✓ Silicone Rubber Insulated with Treated Glass Overbraid
- ✓ Tinned Copper Conductor

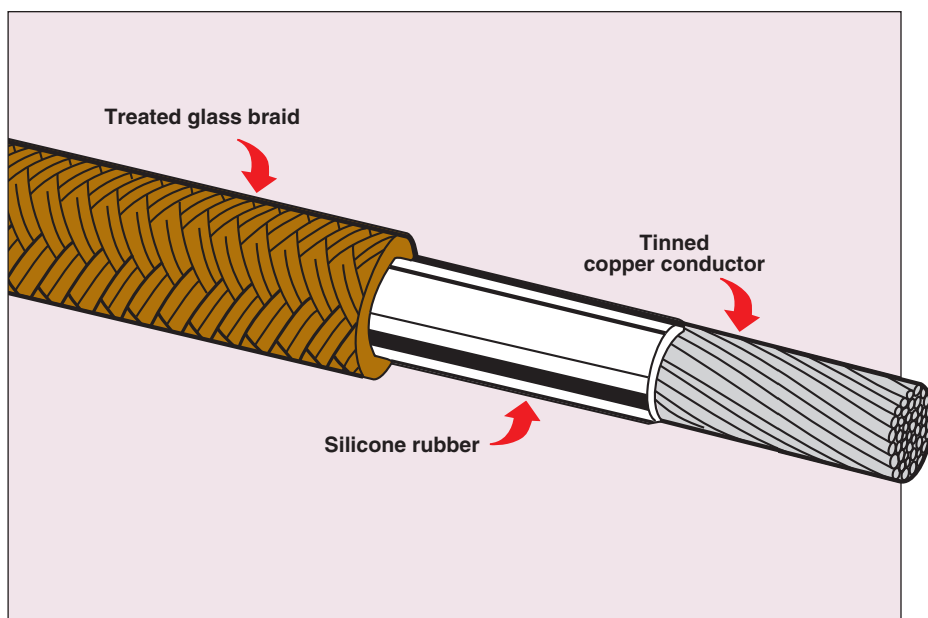

Braided silicone rubber insulated high-temperature lead wires are well suited for use as the exposed leads in appliances and lighting fixtures. HTRG Series wire is also used for range top burners and back panels, steam irons, toasters, broiler ovens, gas dryers, kilns, recessed lighting fixtures and similar applications up to 200°C (392°F).

CAUTION AND WARNING!
Fire and electrical shock may result if products are used improperly or installed or used by nonqualified personnel.

Additional Heater Hook-up Wire Available. Visit omega.com/heatwire for Details.

Discount Schedule	
50 to 99 ft.	10%
100 to 199 ft.	15%
200 to 499 ft.	20%
499 ft. and up	25%

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)							
Gage	Model No.	Price/ft	Type	Volts	Nominal OD mm (in)	Approx Wt kg/300 m (lb/1000')	Color
18	HTRG-1CU-618SW	\$0.45	7 x 26	600	3.2 (0.13)	5.7 (12.5)	White
18	HTRG-1CU-618SBK	0.45	7 x 26	600	3.2 (0.13)	5.7 (12.5)	Black
16	HTRG-1CU-616SW	0.50	7 x 24	600	3.4 (0.13)	7.5 (16.5)	White
16	HTRG-1CU-616SBK	0.50	7 x 24	600	3.4 (0.13)	7.5 (16.5)	Black
14	HTRG-1CU-614SW	0.65	7 x 22	600	3.8 (0.15)	10.0 (22.0)	White
14	HTRG-1CU-614SBK	0.65	7 x 22	600	3.8 (0.15)	10.0 (22.0)	Black
12	HTRG-1CU-612SW	0.90	19 x 25	600	4.2 (0.17)	14.3 (31.5)	White
12	HTRG-1CU-612SBK	0.90	19 x 25	600	4.2 (0.17)	14.3 (31.5)	Black
10	HTRG-1CU-610SW	1.35	19 x 23	600	5.6 (0.22)	23.1 (51.0)	White
10	HTRG-1CU-610SBK	1.35	19 x 23	600	5.6 (0.22)	23.1 (51.0)	Black

Standard Conductors: AWG 22-20: Nickel Plated Copper or AWG 18-8: Tinned Copper.
Standard Color: White or black. Other colors available; contact Sales.
 * HTRG Series wire is both UL listed and CSA certified.
 See heater hook-up wire introduction for current carrying capacity and derating.
Ordering Example: HTRG-1CU-616SW, a 50' spool of 16 gage stranded wire with white jacketing, \$0.50 x 50 = \$25 (less 20% discount) = **\$20.**



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters