




## Micro-DC Extension Cable Assemblies For Probes, Sensors and Transmitters

M12C Series  
Starts at  
**\$10**

- ✓ Extension Cables with M12 Female Connector (One End) and Stripped Leads (Other End)
- ✓ Gold Plated Contacts
- ✓ PVC, Polyurethane and Silicone Rubber Jacket/Insulation
- ✓ Available in Various Lengths
- ✓ Straight or Right Angle Connection

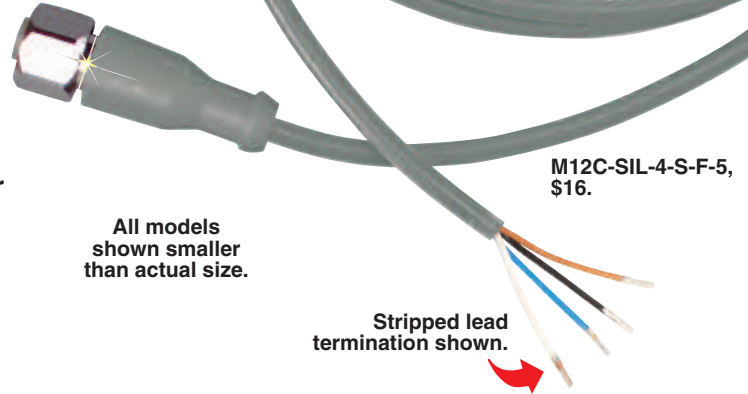

All models shown smaller than actual size.

M12C-SIL-4-S-F-5, \$16.

Highly flexible polyurethane cables for Automation applications.

Nickel plated brass nut.

M12C-PUR-4-R-F-5 with right angle connector, \$16.50.      M12C-PUR-4-S-F-5, \$16.50.

Rugged PVC jacketed cables for wash-down applications.


316 SS nut.

M12C-PVC-4-R-F-5 with right angle connector, \$15.50.      M12C-PVC-4-S-F-5, \$15.50.

Field mountable M12 connectors shown actual size.

M12-R-F-FM, \$11.      M12-S-F-FM, \$11.  
M12-R-M-FM, \$11.      M12-S-M-FM, \$11.

Visit [omega.com/m8-m12fm](http://omega.com/m8-m12fm) for dimensions and ordering information.

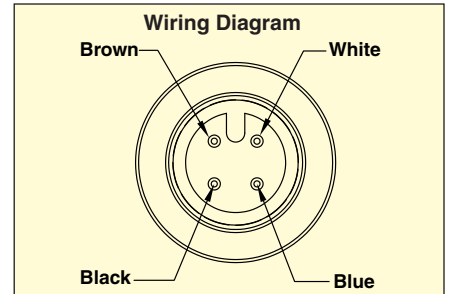

Color Codes			
Pin 1	Pin 2	Pin 3	Pin 4
Brown	White	Blue	Black

**MOST POPULAR MODELS HIGHLIGHTED!**

### To Order (Specify Model Number)

Model No.	Connection #1	Connection #2	Length	Price		
				Polyurethane	PVC	Silicone
M12C-(*)-4-S-F-1.5	Straight M12 4-pin female	Stripped leads	1.5 m (5')	—	—	\$10.00
M12C-(*)-4-S-F-2	Straight M12 4-pin female	Stripped leads	2 m (6.5')	\$13.50	—	—
M12C-(*)-4-S-F-3	Straight M12 4-pin female	Stripped leads	3 m (10')	—	—	13.00
M12C-(*)-4-S-F-5	Straight M12 4-pin female	Stripped leads	5 m (16.4')	16.50	\$15.50	16.00
M12C-(*)-4-S-F-10	Straight M12 4-pin female	Stripped leads	10 m (32.6')	19.50	18.50	19.00
M12C-(*)-4-S-F-15	Straight M12 4-pin female	Stripped leads	15 m (48.9')	—	—	22.00
M12C-(*)-4-S-F-20	Straight M12 4-pin female	Stripped leads	20 m (65.2')	—	—	25.00
M12C-(*)-4-R-F-1.5	Right angled M12 4-pin female	Stripped leads	1.5 m (5')	—	—	10.00
M12C-(*)-4-R-F-2	Right angled M12 4-pin female	Stripped leads	2 m (6.5')	13.50	—	—
M12C-(*)-4-R-F-3	Right angled M12 4-pin female	Stripped leads	3 m (10')	—	—	13.00
M12C-(*)-4-R-F-5	Right angled M12 4-pin female	Stripped leads	5 m (16.4')	16.50	15.50	16.00
M12C-(*)-4-R-F-10	Right angled M12 4-pin female	Stripped leads	10 m (32.6')	19.50	18.50	19.00
M12C-(*)-4-R-F-15	Right angled M12 4-pin female	Stripped leads	15 m (48.9')	—	—	22.00
M12C-(*)-4-R-F-20	Right angled M12 4-pin female	Stripped leads	20 m (65.2')	—	—	25.00

(\*) Add "PUR" for Polyurethane, "PVC" for PVC or "SIL" for silicone insulated cable.

Ordering Examples: M12C-PVC-4-R-F-5, M12C series cable assembly, right angle connection, PVC cable, 5 m (16.4') L, \$15.50.  
M12C-PUR-4-S-F-2, M12C series cable assembly, straight connection, polyurethane cable, 2 m (6.5') L, \$13.50.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters