


Jack Panels With Color-Coded Miniature Connectors

- ✓ Snap-in Assemblies
- ✓ Numbered Circuits
- ✓ Off-the-Shelf Sizes
- ✓ Accepts All Miniature Male Connectors
- ✓ 2.3 mm (0.09") Thick Anodized Aluminum Panels
- ✓ Free Dust Caps Included with Each Panel



3.3 mm
(0.13") Dia

3.3 mm
(0.13")

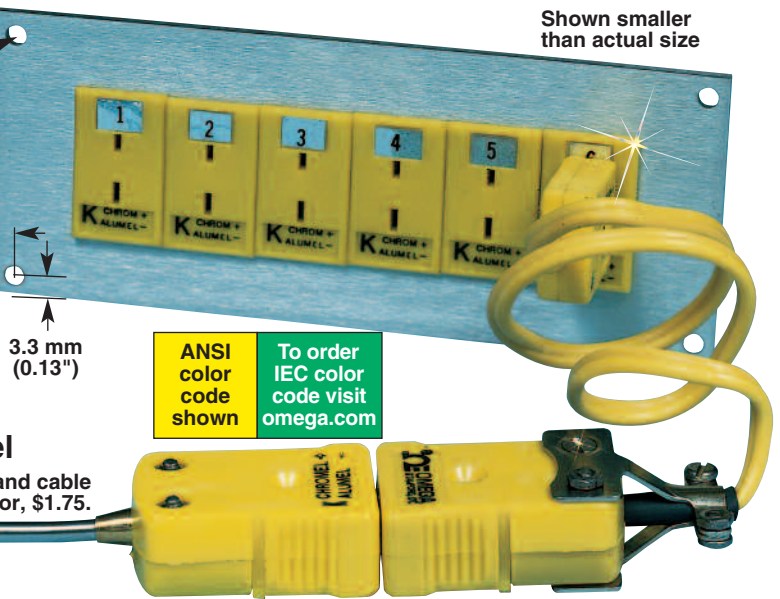


Shown smaller
than actual size

ANSI
color
code
shown

To order
IEC color
code visit
omega.com

CASS-316U-12 probe includes free mating connector and cable clamp, \$30, EXPP-K-24-25 wire, \$22, SMPW-K-M connector, \$1.75.

Mounts in a
Rectangular
Cutout

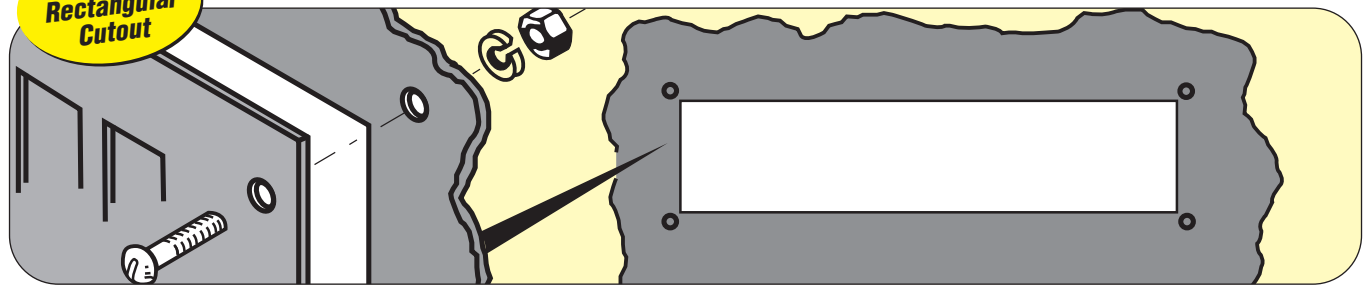


Custom Panels

OMEGA® Miniature Jack Panels are fabricated using miniature panel jacks and snap strip assemblies in a clear anodized aluminum plate. Some prices for OMEGA's panels with miniature color-coded jacks are listed below. Because of the infinite variety of panel sizes and the different thermocouple calibrations, we are not able to list all prices. Special panels are available with switches, meter or both. Please consult the Sales Department for price on any configuration not listed below. Specify number of rows, total number of jacks and calibration. All prices include panel and jacks.

The connector bodies are molded from high-impact plastic and have a maximum service temperature of 205°C (401°F). The panels are machined from rugged 2.3 mm (0.09") aluminum with a brushed finish. Clear anodizing adds durability and corrosion resistance.

Extra Dust Caps:
MPJ-CAP, \$5/pkg of 12

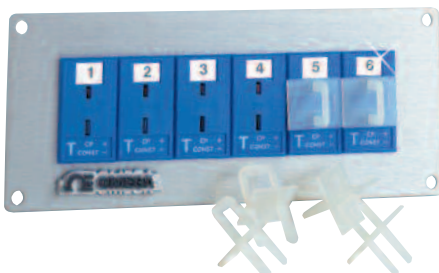

Price and Quantity Discount Information

Prices shown are for J, K, T, E, R, S, N, G, C, D and U calibrations. To price more than one panel of any type, use the following price schedule:

1 Row.....	\$20 per panel, + jacks
2 Rows.....	\$20 per panel, + jacks
3 Rows.....	\$25 per panel, + jacks
4 Rows.....	\$25 per panel, + jacks

Miniature panel jacks,
Model No. **MPJ**: \$2.25 ea.
Use connector quantity discount
schedule at right. Blank panel prices are
not discounted.

Hole Spacing:

3.3 mm (0.13") in on both sides,
3.3 mm (0.13") dia. for mounting hole

Non-Standard Panels:

\$40 minimum order

Discount Schedule	
1-10Net
11-2410%
25-4915%
50-9920%
100 and upConsult Sales

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)

Circuits Per Row	Dimensions in mm (in)	1 Row 45 H (1.75)	2 Rows 83 H (3.25)	3 Rows 108 H (4.25)	4 Rows 133 H (5.25)
6	Model No.	MJP1-06-(*)	MJP2-12-(*)	MJP3-18-(*)	MJP4-24-(*)
111 mm L (4.38")	Price	\$33.50	\$44.30	\$61.45	\$73.60
12	Model No.	MJP1-12-(*)	MJP2-24-(*)	MJP3-36-(*)	MJP4-48-(*)
207 mm L (8.13")	Price	\$44.30	\$68.60	\$93.85	\$116.80
18	Model No.	MJP1-18-(*)	MJP2-36-(*)	MJP3-54-(*)	MJP4-72-(*)
302 mm L (11.88")	Price	\$56.45	\$88.85	\$122.20	\$154.60

Dust caps included.

Note: All OMEGA® MJP jack panels are assembled at no extra cost.

* Insert thermocouple calibration J, K, T, E, R, S, N, G, C, E or U.

Ordering Example: MJP3-54-K, Triple row color-coded jack panel with Type K connector, \$122.20



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters