




Short RTD Probe

PR-20 Series
Starts at
\$60



- 2" Compact Design for Applications with Space Restrictions
- Transitions Directly to Lead Wires (No Transition Fitting)
- Temperature Range:
PFA: -50 to 260°C (-58 to 500°F)
Fiberglass: -50 to 600°C (-58 to 1112°F)
Depending on Cable Selection
- High-Accuracy, 100 Ω, Class "A" DIN Platinum Elements per IEC751 (alpha = 0.00385 Ω/Ω/°C)
- 2-, 3-, 4-Wire Constructions Available

These general purpose 2" long sensors can be used in most liquid and air applications. When used in liquid environments, the epoxy-sealed end should not be immersed

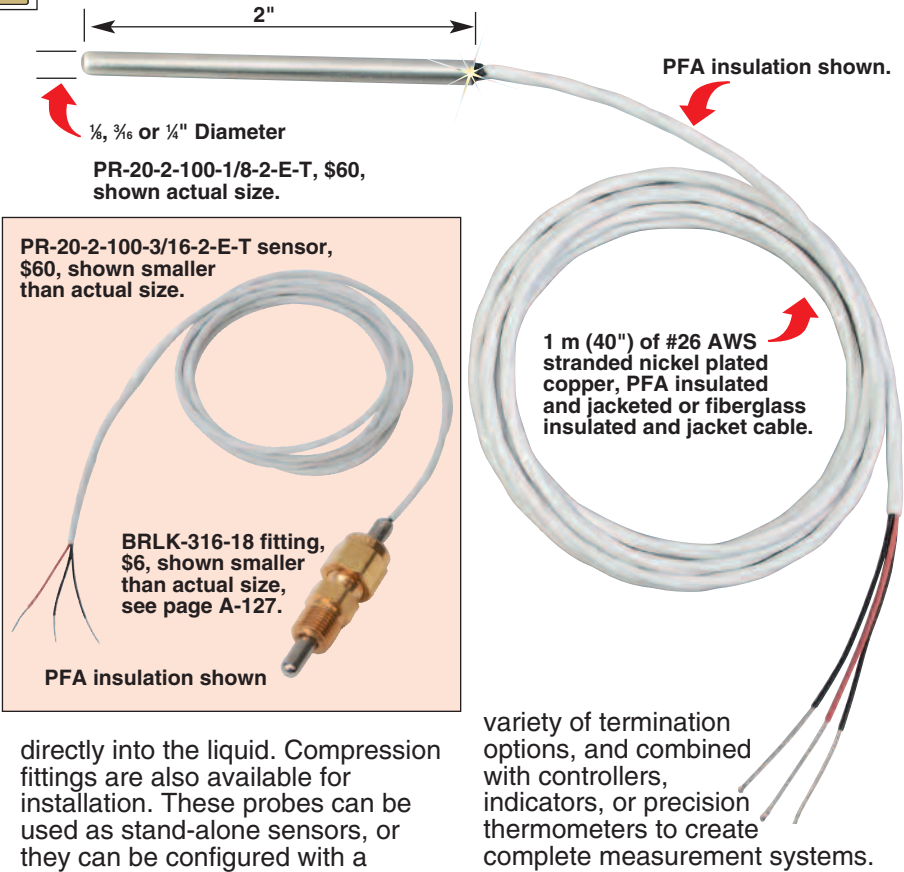

MOST POPULAR MODELS HIGHLIGHTED!

To Order (Specify Model Number)				
Model Number	Price	Probe Diameter (inch)	Lead Wire Style*	Max Temp Range °C (°F)
PR-20-2-100-1/8-2-E-T	\$60	1/8	3-wire/PFA insulation	260 (500)
PR-20-2-100-3/16-2-E-T	60	3/16	3-wire/PFA insulation*	260 (500)
PR-20-2-100-1/4-2-E-T	65	1/4	3-wire/PFA insulation*	260 (500)
PR-20-2-100-1/8-2-E-G	60	1/8	3-wire/fiberglass insulation	600 (1112)
PR-20-2-100-3/16-2-E-G	60	3/16	3-wire/fiberglass insulation*	600 (1112)
PR-20-2-100-1/4-2-E-G	65	1/4	3-wire/fiberglass insulation*	600 (1112)

Note: For leads longer than 40", add "(-desired length in inches)" to the model number and add \$2.25/ft.

* For 4 wire configurations change the "2" to a "3" in the model number and add \$15 to price.

4-wire constructions are not available in 1/8" diameters.

Terminations Available: for "-LUG" add \$4.50, for "-OTP" and "-MTP" connectors add \$7.

Ordering Example: PR-20-2-100-3/16-2-E-T, 2", 3/16" diameter, 3-wire 100 Ω RTD probe with 40" PFA insulated lead wire, \$60.

Accessories

Model Number	Price	Description
MTP-U-M	\$2.50	Miniature male 3-prong flat pin connector
OTP-U-M	3.50	Heavy-duty male 3-prong round pin connector
DPi32	150.00	1/2 DIN panel meter
SSLK-18-18	12.00	Compression fitting for 1/8" probe with 1/8 male NPT
SSLK-14-14	11.00	Compression fitting for 1/4" probe with 1/4 male NPT
SSLK-316-14	14.00	Compression fitting for 3/16" probe with 1/4 male NPT
SSLK-316-18	12.00	Compression fitting for 3/16" probe with 1/8 male NPT



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters