



Sanitary RTD Assemblies

Standard Duty with Protection Head

PRS-S-NB9W Series

\$95

All Models



**For Use in
CIP and Sanitary
Processes**


- ✓ Standard Duty 1/4" Probe Diameter
- ✓ 1 1/2" 16 AMP Tri-Grip™ (Tri-Clamp® Compatible) Fitting Standard
- ✓ White Polypropylene Head with Screw Cap Standard, Optional 316L SS Head Available
- ✓ 316L SS Wetted Surfaces with 32 µin or Better Finish
- ✓ 4-Wire Pt100 Class A Element Standard
- ✓ -50 to 200°C (-58 to 392°F) Temperature Range

Options

- ✓ Fitting Styles
- ✓ Protection Heads
- ✓ Probe Lengths
- ✓ RTD Elements


**Sensor Flange Size
Range 3/4" to 4" Tri-Grip™
Process Flange.
See Page C-16 for
Details**

The OMEGA® PRS-S-NB9W Series RTD probe assemblies are available in standard lengths from 3 to 6", with a 4-wire Pt100 Class A element (100 ±0.06 Ω at 0°C) that is compatible with 3-wire RTD instrumentation. Standard features include a 1 1/2" 16 AMP Tri-Grip™ fitting, type NB9W white polypropylene protection head with screw cap. Please consult sales for available options, including element types and curves, probe lengths, protection heads and sanitary fitting styles.

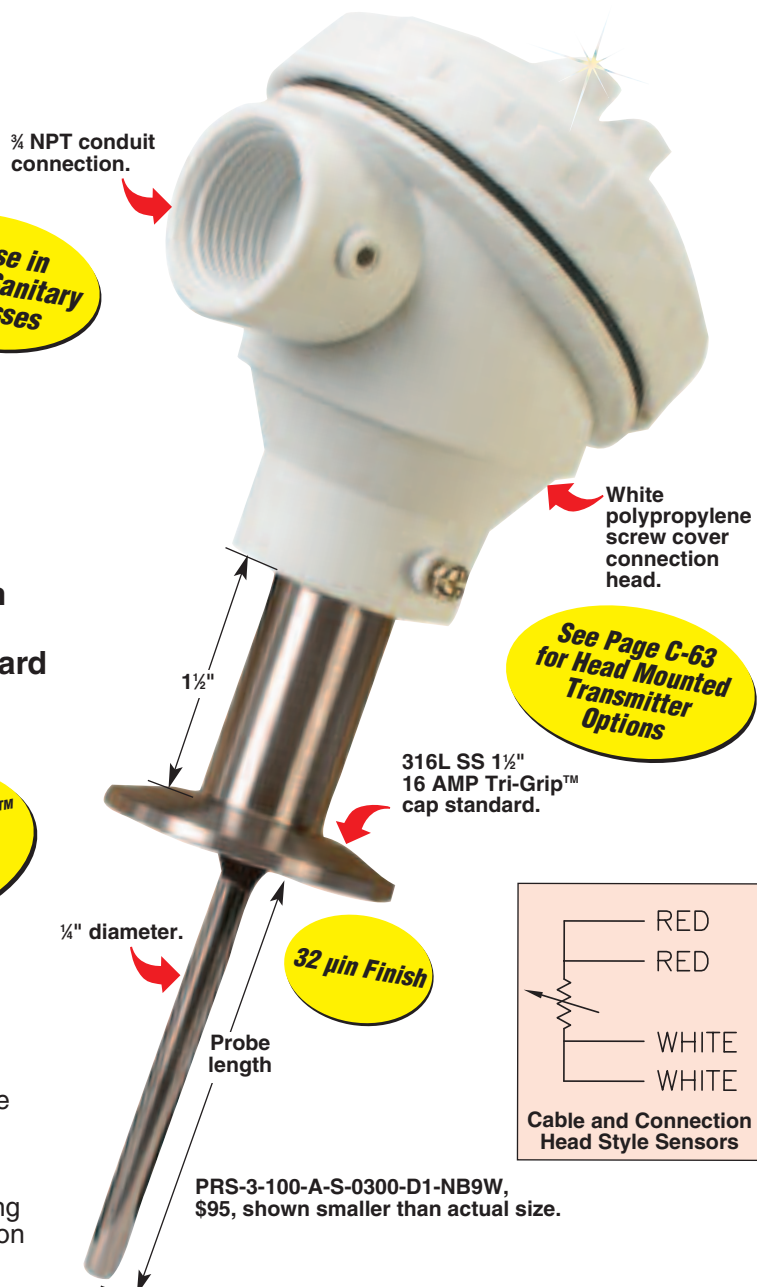

**See Page C-63
for Head Mounted
Transmitter
Options**

32 µin Finish

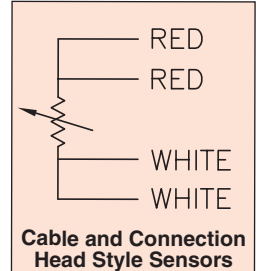

PRS-3-100-A-S-0300-D1-NB9W, \$95, shown smaller than actual size.

MOST POPULAR MODEL HIGHLIGHTED!

To Order (Specify Model Number)					
Model No.	Price	Lead Wire Style	Ω at 0°C	Sheath Diameter	Probe Length
PRS-3-100-A-S-0300-D1-NB9W	\$95	4-wire	100	1/4"	3"
PRS-3-100-A-S-0400-D1-NB9W	95	4-wire	100	1/4"	4"
PRS-3-100-A-S-0500-D1-NB9W	95	4-wire	100	1/4"	5"
PRS-3-100-A-S-0600-D1-NB9W	95	4-wire	100	1/4"	6"

Optional protection heads: To order with NB15 large 316 SS head, change model number suffix from "-NB9W" to "-NB15" and add \$37 to price.
Note: Please consult sales for available options, including element types and curves, probe lengths, and sanitary fitting styles.
Ordering Examples: PRS-3-100-A-S-0400-D1-NB9W, 4-wire Pt100 RTD sensor (100 Ω @ 0°C, Class A accuracy), 1 1/2" 16 AMP Tri-Grip™ fitting, 4" length, standard duty probe, NB9W white polypropylene screw cap protection head, \$95.
 PRS-3-100-A-S-0400-D1-NB15, 4-wire Pt100 RTD sensor (100 Ω @ 0°C, Class A accuracy), 1 1/2" 16 AMP Tri-Grip™ fitting, 4" length, standard duty probe with NB15 316 SS screw top cap protection head, \$95 + 37 = \$132.

Sanitary RTD Assemblies

Heavy-Duty with Protection Head



PRS-H-NB9W Series

\$125

All Models



- ✓ Heavy-Duty Probe Design With Stepped Probe Stem for Additional Strength
- ✓ 1½" 16 AMP Tri-Grip™ (Tri-Clamp® Compatible) Fitting Standard
- ✓ White Polypropylene Head with Screw Cap Standard, Optional 316L SS Connection Head Available
- ✓ 316L SS Wetted Surfaces with 32 µin or Better Finish
- ✓ 4-Wire Pt100 Class A Element Standard
- ✓ -50 to 200°C (-58 to 392°F) Temperature Range

Options



- ✓ Fitting Styles
- ✓ Protection Heads
- ✓ Probe Lengths
- ✓ RTD Elements

Sensor Flange Size Range ¾" to 4" Tri-Grip™ Process Flange. See Page C-16 for Details

For Use in CIP and Sanitary Processes

See Page C-63 for Head Mounted Transmitter Options

32 µin Finish

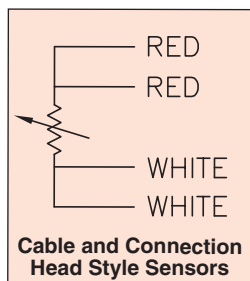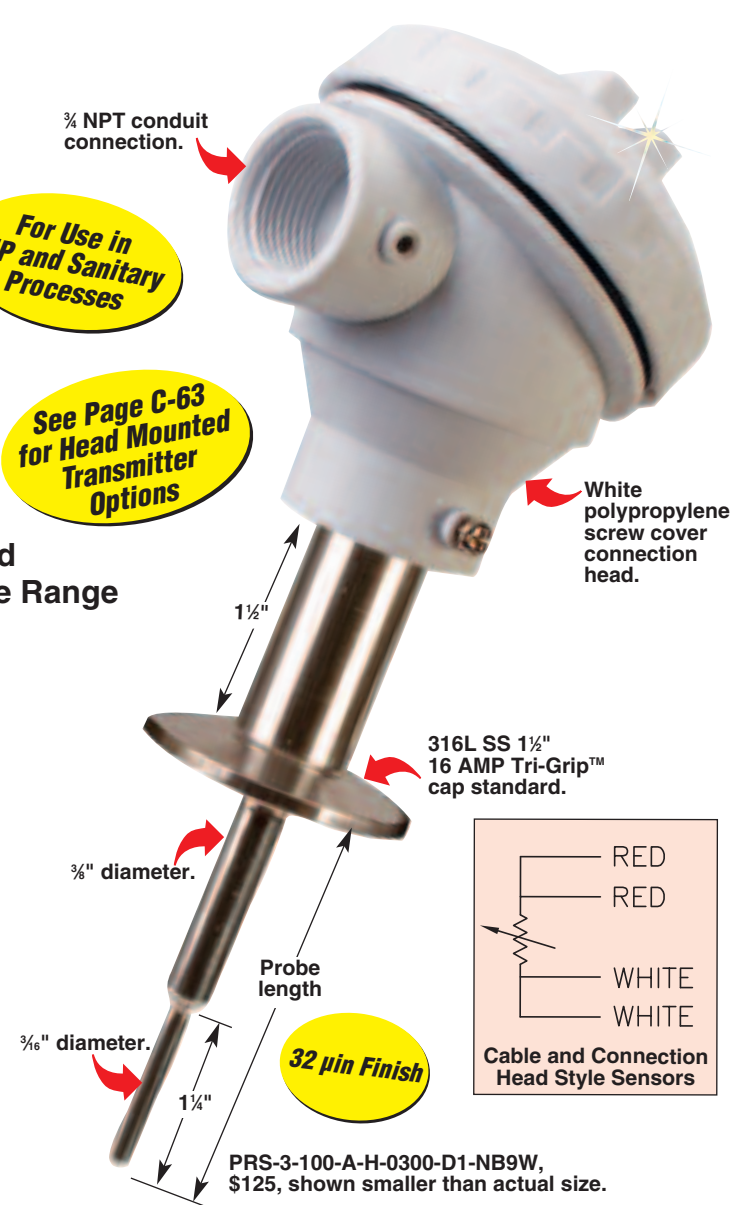

The OMEGA® PRS-H-NB9W Series RTD probe assemblies are available in standard lengths from 3 to 6", with a 4-wire Pt100 Class A element (100 ±0.06Ω at 0°C) that is compatible with 3-wire RTD instrumentation. These heavy-duty probes have a ¾" diameter, which steps down to a 3/16" dia at the probe tip, for fast response and additional strength. Standard features include a 1½" 16 AMP Tri-Grip™ fitting, type NB9W white polypropylene protection head with screw cap. Please consult sales for available options, including element types and curves, probe lengths, protection heads and sanitary fitting styles.

PRS-3-100-A-H-0300-D1-NB9W, \$125, shown smaller than actual size.

MOST POPULAR MODEL HIGHLIGHTED!

To Order (Specify Model Number)					
Model No.	Price	Lead Wire Style	Ω at 0°C	Sheath Diameter	Probe Length
PRS-3-100-A-H-0300-D1-NB9W	\$125	4-wire	100	¾"	3"
PRS-3-100-A-H-0400-D1-NB9W	125	4-wire	100	¾"	4"
PRS-3-100-A-H-0500-D1-NB9W	125	4-wire	100	¾"	5"
PRS-3-100-A-H-0600-D1-NB9W	125	4-wire	100	¾"	6"

Optional protection heads: To order with NB15 large 316 SS head, change model number suffix from "-NB9W" to "-NB15" and add \$37 to price.
Note: Please consult sales for available options, including element types and curves, probe lengths, and sanitary fitting styles.
Ordering Examples: PRS-3-100-A-H-0400-D1-NB9W, 4-wire Pt100 RTD sensor (100 Ω @ 0°C, Class A accuracy), 1½" 16 AMP Tri-Grip™ fitting, 4" length, heavy-duty probe, NB9W white polypropylene screw cap protection head, \$125.
 PRS-3-100-A-H-0400-D1-NB15, 4-wire Pt100 RTD sensor (100 Ω @ 0°C, Class A accuracy), 1½" 16 AMP Tri-Grip™ fitting, 6" length, heavy-duty probe, NB15 316 SS screw cap protection head, \$125 + 37 = \$162.



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters