


Connector Accessories For Miniature Size Connectors

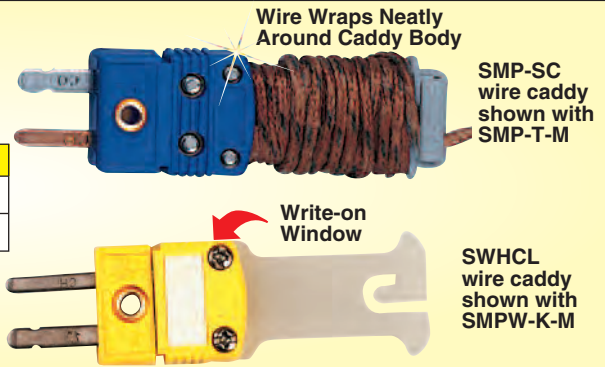

Wire Caddy (Spool Cap)


Model No.	Price Pkg	Compatible Connectors
SMP-SC	\$3.00/pkg of 5	SMPW, HMPW
SWHCL	7.50/pkg of 20	SMPW, HMPW



Dual Element Tube Clamp

Model No.	Price	Compatible Connectors
DX-BRLK-(*)-SMP	\$7.00	SMPW, HMPW

*Insert probe diameter: "116" for 1/16", or "18" for 1/8"

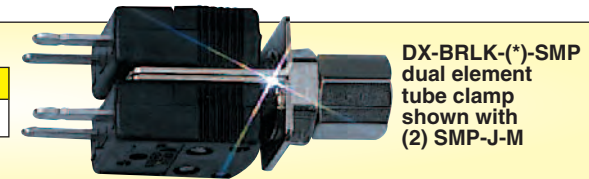


Ferrite Cable Clamp

Model No.	Price	Compatible Connectors
PCLM-SMP-FT	\$2.50	SMPW, GMP, HGMP
PCLM-SMP-RSC-FT	2.50	HMPW, MTP



Cable Clamp


Model No.	Price	Compatible Connectors
PCLM-SMP	\$1.00	SMPW, HMPW
PCLM-NMP	1.00	NMP
PCLM-GMP	1.00	GMP, HGMP
PCLM-SMP-RSC	1.00	SMPW, HMPW (larger size wire)
PCLM-SHX	1.00	SHX-MF

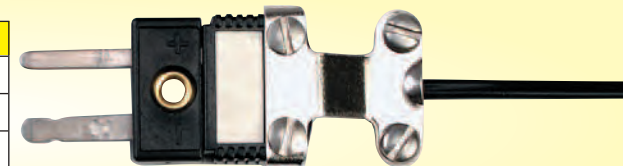

Miniature Strain Relief Tubing

Model No.	Price/Pkg	Compatible Connectors
MSRT-116-(*)	See Note Below	SMPW, HMPW, GMP, HGMP
MSRT-332-(*)		
MSRT-532-10	\$0.50	

*Insert quantity: select from 5/\$0.30, 10/\$0.50, 50/\$2.50, 100/\$5.00. Center number denotes tubing inside diameter: "316" for 3/16", "332" for 3/32", "532" for 5/32".

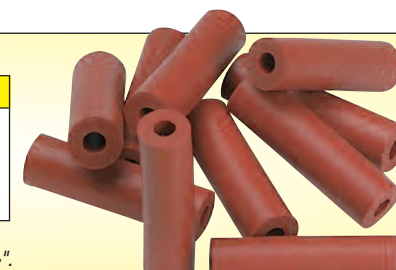

Rubber Boots

Model No.	Price/Pair	Compatible Connectors
MRB	\$1.50	SMPW, HMPW
MRBS	3.00	SMPW, HMPW

MRB rated to 200° MRBS rated to 450°



Connector Accessories For Miniature Size Connectors



Safety Clip

Model No.	Price/Pkg of 10	Compatible Connectors
SMCL	\$1.00	SMPW, GMP, HMPW, HGMP
FMCL	1.00	FMP, FMPW, HFMP, HFMPW


Safety clip SMCL

Shown with GMP-T-MF




Panel Mounting Bracket (Standard and Round Hole)

Model No.	Price	Compatible Connectors	"A" Dimension
SMACL	\$2.00	SMPW, GMP, HMPW, HGMP	0.88"
MACL	2.00	NMP	0.88"
SRMACL	2.00	SMPW, GMP, HMPW, HGMP	0.67"
RMACL	2.00	NMP	0.67"

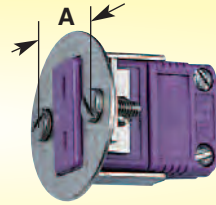

SRMACL round hole panel mounting bracket.

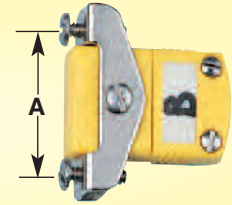

SMACL panel mounting bracket.



Wire Hole Reducer-For Smaller Gauge Wires SMPW Connectors

Model No.	Price/Pkg of 20	Reduced Hole Opening
RB-SMP-100	\$1.00	2.54 (0.100") Dia.
RB-SMP-140	1.00	3.55 (0.140") Dia.




RB-SMP-100 wire hole reducers shown with SMPW-K-M

Dimensions: mm (in)

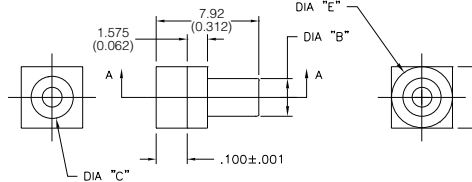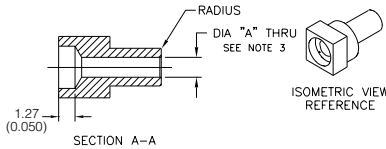

©
.186^{+0.0020}
-0.0030
SQUARE

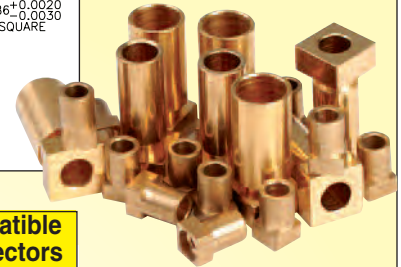

Crimp Style Bushing

Model Number	Dia A-ID mm (in)	Dia B-OD mm (in)	Dia C mm (in)	Dia E mm (in)	Compatible Connectors
(*)B-SMP-CR020-(**)	0.56(0.022)	2.95 (0.116)	3.25 (0.128)	4.72 (0.186)	SHX, NMP, MTP, GMP, SMP, SMPW, FMPW
(*)B-SMP-CR032-(**)	0.89 (0.035)	2.95 (0.116)	3.25 (0.128)	4.72 (0.186)	
(*)B-SMP-CR040-(**)	1.09 (0.043)	2.95 (0.116)	3.25 (0.128)	4.72 (0.186)	
(*)B-SMP-CR1.5MM-(**)	1.57 (0.062)	2.95 (0.116)	3.25 (0.128)	4.72 (0.186)	
(*)B-SMP-CR062-(**)	1.65 (0.065)	2.95 (0.116)	3.25 (0.128)	4.72 (0.186)	
(*)B-SMP-CR093-(**)	2.44 (0.096)	4.72 (0.186)	3.96 (0.156)	N/A	
(*)B-SMP-CR3.0mm-(**)	3.10 (0.122)	4.72 (0.186)	3.96 (0.156)	N/A	
(*)B-SMP-CR125-(**)	3.25 (0.128)	4.72 (0.186)	3.96 (0.156)	N/A	

(*) Insert "B" for brass or "S" for stainless steel
(**) Insert quantity: "10" or "100." "CR" number indicates compatible probe diameter.

To order crimping tool for use with these bushings, specify model number **BB-SMT-CT**, \$177.

Brass price, pack of 10 is \$5, pack of 100 is \$20.

Stainless steel price, pack of 10 is \$10, pack of 100 is \$40.

Ordering Example: **SB-SMP-CR040-100** pkg of 100 crimp style stainless steel bushing for 0.040 diameter probe, \$40.

Clamp Grommets Silicone 0.25" long

Model No.	Price Per pkg	Inside Diameter	Outside Diameter	Length	Compatible Connectors
SSRT-CC-018-(*)	See Note Below	3.18 (0.125)	4.77 (0.188)	6.35 (0.250)	OSTW Male or Female
SSRT-CC-332-(*)		2.38 (0.094)			
SSRT-CC-116-(*)		1.59 (0.063)			
SSRT-CC-132-(*)		0.79 (0.032)			

*Insert pkg quantity: select from 5/\$0.30, 10/\$0.50, 50/\$2.50, 100/\$5.00

Center number denotes grommet inside diameter for 0.75" long strain relief tubing see accessories page G-33



PATENTED
Covered by U.S and International patents and pending applications



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters