



Utility Handle Probe

THX-400-H Series
Starts at
\$91



- ✓ Economical and Accurate Probe With Easy-Grip Molded Handle
- ✓ 300 mm (12") L Probe Can be Stored in Tool Boxes or Other Locations for Easy Access
- ✓ Retractable Cable Extends to 1.5 m (5') Standard Termination Has Stripped Leads
- ✓ Max Temperature 150°C (212°F) for Sensor, 135°C (275°F) for Handle
- ✓ 4.5 mm ($\frac{3}{16}$ ") Diameter, 300 Series Stainless Steel Sheath

THX-400-H-12, \$91, shown smaller than actual size.

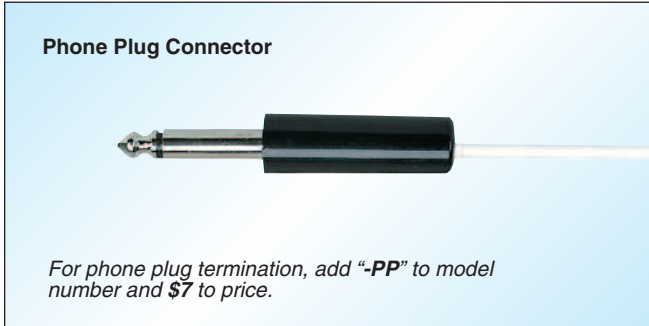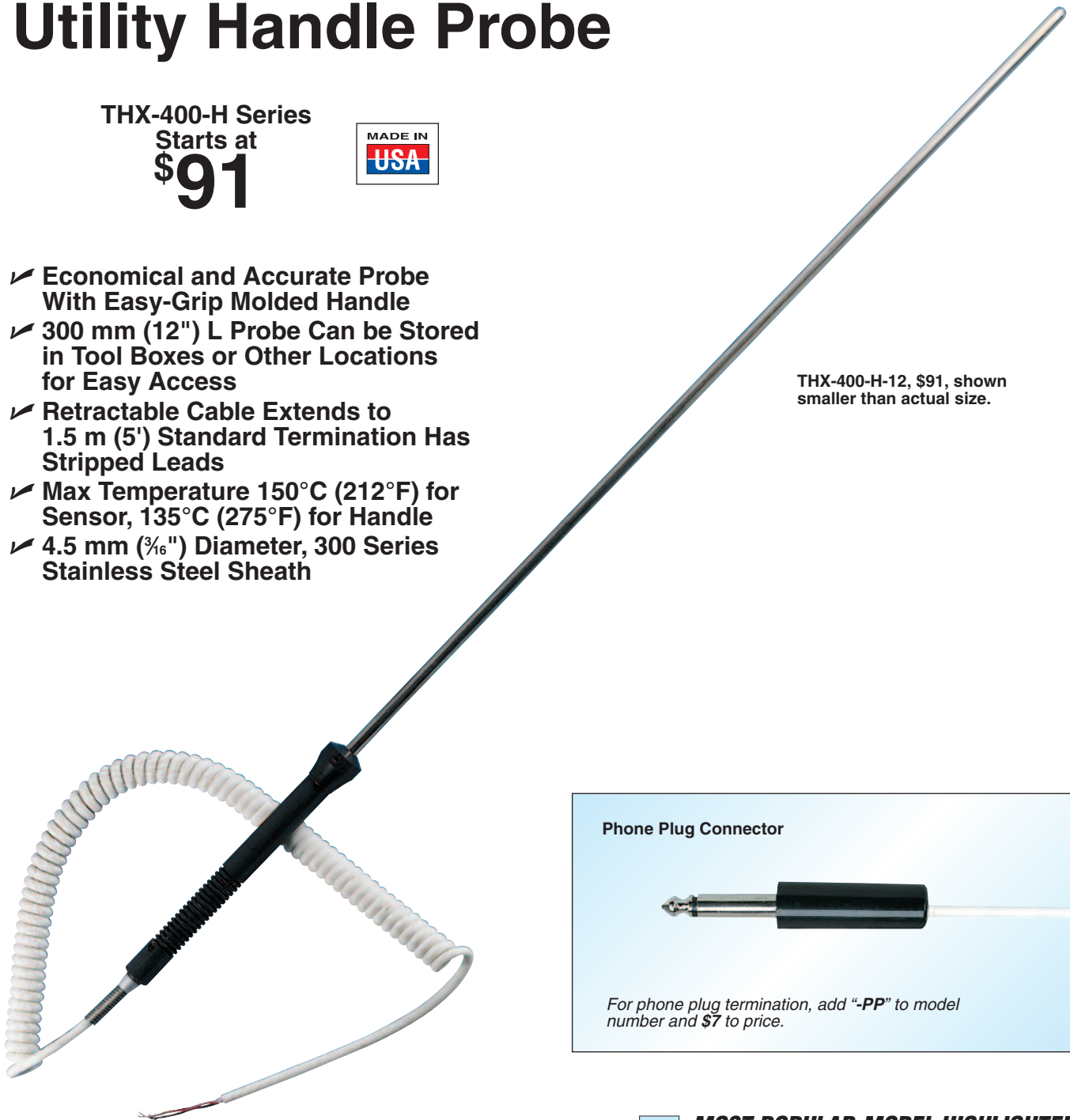

MOST POPULAR MODEL HIGHLIGHTED!

To Order (Specify Model Number)						
Model Number	Price	Resistance @ 25°C	Interchangeability @ 0 to 70°C	Sheath Length	Sheath Diameter	Cable Termination
THX-400-H-12	\$91	2252 Ω	±0.2°C	300 mm (12")	4.5 mm ($\frac{3}{16}$ ")	Stripped
THX-400-H-18	94	2252 Ω	±0.2°C	450 mm (18")	4.5 mm ($\frac{3}{16}$ ")	Stripped
THX-400-H-24	97	2252 Ω	±0.2°C	600 mm (24")	4.5 mm ($\frac{3}{16}$ ")	Stripped

Notes: For a phone plug, add "-PP" to the model number and \$7 to the price.

Ordering Examples: THX-400-H-12, utility handle probe, 300 mm (12") long with retractable cable and stripped lead terminations, \$91.

THX-400-H-12-PP, utility handle probe, 300 mm (12") long with retractable cable and phone plug termination, \$91 + 7 = \$98.

Accessory

Model Number	Price	Description
CL26	\$950	High-precision handheld calibrator



UNITED STATES

www.omega.com
1-800-TC-OMEGA
Stamford, CT.

CANADA

www.omega.ca
Laval(Quebec)
1-800-TC-OMEGA

GERMANY

www.omega.de
Deckenpfronn, Germany
0800-8266342

UNITED KINGDOM

www.omega.co.uk
Manchester, England
0800-488-488

FRANCE

www.omega.fr
Guyancourt, France
088-466-342

CZECH REPUBLIC

www.omegaeng.cz
Karviná, Czech Republic
596-311-899

BENELUX

www.omega.nl
Amstelveen, NL
0800-099-33-44



More than 100,000 Products Available!

• Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

• Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

• pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

• Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

• Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

• Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters