

# Non-Reversible OMEGALABEL<sup>®</sup> Temperature Labels

TL-8 and TL-10  
Range Series

- ✓ Adhesive Backs for Easy Mounting for Temperatures Above -40°C/°F
- ✓ Indicator Turns Black When Exposed


pkg of 10    pkg of 30  
**\$13**    **\$36**

## Specifications

**Accuracy:** Up to 99°C (210°F) is ±1°C (1.8°F);  
From 100°C (212°F) to 154°C (309°F) is ±1.5°C (2.7°F);  
From 160°C (320°F) to 280°C (536°F) is ±1% and ±1°C (1.8°F)



Confirm correct shipping of critical products.

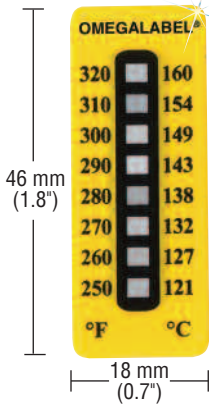

**TL-8 SERIES,**  
8-Temperature Range Labels  
46 x 18 mm (1.8 x 0.7")

**MOST POPULAR  
MODELS HIGHLIGHTED!**

Model No.	Temperature Range										
TL-8-105(*)	°F	105	110	115	120	130	140	150	160		
	°C	40	43	46	49	54	60	66	71		
TL-8-170(*)	°F	170	180	190	200	210	220	230	240		
	°C	77	82	88	93	99	104	110	116		
TL-8-250(*)	°F	250	260	270	280	290	300	310	320		
	°C	121	127	132	138	143	149	154	160		
TL-8-330(*)	°F	330	340	350	360	370	380	390	400		
	°C	166	171	177	182	188	193	199	204		
TL-8-410(*)	°F	410	420	435	450	465	480	490	500		
	°C	210	216	224	232	241	249	254	260		

TL-8-250,  
shown  
actual size.

\* Insert "-10" for package of 10 or "-30" for package of 30.  
**Ordering Example:** TL-8-170-30, 8 temperature range labels (170, 180, 190, 200, 210, 220, 230, 240°F), package of 30, \$36.


## Applications

- General • Aeronautical • Electrical • HVAC
- All applications where size is not a conditioning factor

pkg of 10    pkg of 30  
**\$13<sup>50</sup>**    **\$37**

TL-10-105,  
shown  
actual size.

54 mm  
(2.1")

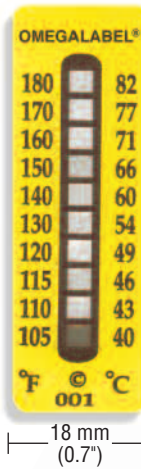

**TL-10 SERIES,** 10-Temperature Range Labels  
54 x 18 mm (2.1 x 0.7")

Model No.	Temperature Range										
TL-10-105(*)	°F	105	110	115	120	130	140	150	160	170	180
	°C	40	43	46	49	54	60	66	71	77	82
TL-10-190(*)	°F	190	200	210	220	230	240	250	260	270	280
	°C	88	93	99	104	110	116	121	127	132	138
TL-10-290(*)	°F	290	300	310	320	330	340	350	360	370	380
	°C	143	149	154	160	166	171	177	182	188	193
TL-10-390(*)	°F	390	400	410	420	435	450	465	480	490	500
	°C	199	204	210	216	224	232	241	249	254	260

\* Insert "-10" for package of 10 or "-30" for package of 30.  
**Ordering Example:** TL-10-105-30, 10 temperature range labels (105, 110, 115, 120, 130, 140, 150, 160, 170, 180°F), package of 30, \$37.

Test PC  
board  
components.

See Page  
F-8 to Order

Shown  
smaller than  
actual size.



#### UNITED STATES

[www.omega.com](http://www.omega.com)  
1-800-TC-OMEGA  
Stamford, CT.

#### CANADA

[www.omega.ca](http://www.omega.ca)  
Laval(Quebec)  
1-800-TC-OMEGA

#### GERMANY

[www.omega.de](http://www.omega.de)  
Deckenpfronn, Germany  
0800-8266342

#### UNITED KINGDOM

[www.omega.co.uk](http://www.omega.co.uk)  
Manchester, England  
0800-488-488

#### FRANCE

[www.omega.fr](http://www.omega.fr)  
Guyancourt, France  
088-466-342

#### CZECH REPUBLIC

[www.omegaeng.cz](http://www.omegaeng.cz)  
Karviná, Czech Republic  
596-311-899

#### BENELUX

[www.omega.nl](http://www.omega.nl)  
Amstelveen, NL  
0800-099-33-44



## More than 100,000 Products Available!

### • Temperature

Calibrators, Connectors, General Test and Measurement Instruments, Glass Bulb Thermometers, Handheld Instruments for Temperature Measurement, Ice Point References, Indicating Labels, Crayons, Cements and Lacquers, Infrared Temperature Measurement Instruments, Recorders Relative Humidity Measurement Instruments, RTD Probes, Elements and Assemblies, Temperature & Process Meters, Timers and Counters, Temperature and Process Controllers and Power Switching Devices, Thermistor Elements, Probes and Assemblies, Thermocouples Thermowells and Head and Well Assemblies, Transmitters, Wire

### • Flow and Level

Air Velocity Indicators, Doppler Flowmeters, Level Measurement, Magnetic Flowmeters, Mass Flowmeters, Pitot Tubes, Pumps, Rotameters, Turbine and Paddle Wheel Flowmeters, Ultrasonic Flowmeters, Valves, Variable Area Flowmeters, Vortex Shedding Flowmeters

### • pH and Conductivity

Conductivity Instrumentation, Dissolved Oxygen Instrumentation, Environmental Instrumentation, pH Electrodes and Instruments, Water and Soil Analysis Instrumentation

### • Data Acquisition

Auto-Dialers and Alarm Monitoring Systems, Communication Products and Converters, Data Acquisition and Analysis Software, Data Loggers Plug-in Cards, Signal Conditioners, USB, RS232, RS485 and Parallel Port Data Acquisition Systems, Wireless Transmitters and Receivers

### • Pressure, Strain and Force

Displacement Transducers, Dynamic Measurement Force Sensors, Instrumentation for Pressure and Strain Measurements, Load Cells, Pressure Gauges, Pressure Reference Section, Pressure Switches, Pressure Transducers, Proximity Transducers, Regulators, Strain Gages, Torque Transducers, Valves

### • Heaters

Band Heaters, Cartridge Heaters, Circulation Heaters, Comfort Heaters, Controllers, Meters and Switching Devices, Flexible Heaters, General Test and Measurement Instruments, Heater Hook-up Wire, Heating Cable Systems, Immersion Heaters, Process Air and Duct, Heaters, Radiant Heaters, Strip Heaters, Tubular Heaters